

10,7 x 4,8 x 50 mm



Spannung	125 V	Strom	20 A	Typ	Radial
Voltage		Current		Type	



Norm / Standard:

Werknorm / Factory standard

Anschluss / Connection:

Rundstifte, Abstand 5,0 mm
 Oberfläche verzinnt, steckbar und lötlbar /
 Round pins, distance 5,0 mm
 Surface tin-plated, pluggable and solderable

Verpackungsmöglichkeiten / Packing options:

1.000 St. = lose geschüttet in Polybeutel /
 1.000 pcs. = bulk in plastic bag


Bemessungswerte / Ratings:

Art. No.	I _N	U _N [V]	T _N ¹⁾ [°C]	T _H [°C]	T _{max} [°C]
733.102-S	20 A	125	102	66	160
733.115-S	20 A	125	115	82	160
733.125-S	20 A	125	125	90	160
733.130-S	20 A	125	130	97	160
733.136-S	20 A	125	136	102	160
733.150-S	20 A	125	150	117	160

¹⁾ Toleranz / Tolerance: ±2 °C

Legende / Caption:

I_N = Bemessungsstrom / Rated current
 U_N = Bemessungsspannung / Rated voltage
 T_N = Bemessungstemperatur / Rated functioning temp.
 T_H = Haltezeittemperatur / Holding temperature
 T_{max} = max. Grenztemperatur / max. temp. limit

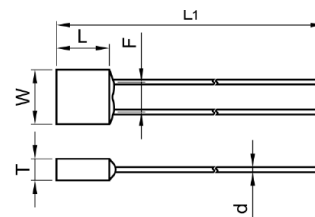

Dimensions (mm)

L	L ₁	W	T	d	F
11.8±0.5	50±2	10.7±0.5	4.8±0.2	Φ1.60±0.05	6.6±0.5