


CL4D07UXXX

(M12 Cordset, 4 Position, 16 AWG Unshielded, Female 90° to Free End)

FEMALE FACE VIEW

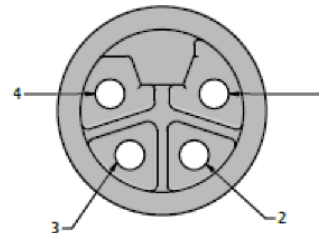

1 → BROWN
2 → GREEN/YELLOW
3 → GRAY
4 → BLACK

- Mueller's CL4D07UXXX is an M12 L coded 4-pin single ended, unshielded instrumentation cable with a 90° female connector on one end and free at the other.
- Keyway – L Coding
- Utilizes a 4-conductor 16 AWG HD-PE-insulated, unshielded cable.
- Ratings:
 - Current: 16 A
 - Voltage: 63V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant