

+ WIRE AND CABLE

MULTICORE CABLE



✓ Active

↓ **PRODUCT DRAWING**
English

> See All Documentation

TE CONNECTIVITY (TE)

44A1121-24-9/9-9

Raychem

44A1121-24-9/9-9

TE Internal Number: 3820583001

Alias ID: 5-1192856-3

EU RoHS Compliant

EU ELV Compliant

Cable Type **Spec 44**Conductor Diameter **.64 mm [.025 in]**Number of Strands **19**Strand Size (AWG) **36**Overall Outside Diameter **3 mm [.118 in]**

> See All Features

North America ▾

Contact us to request pricing, availability and customization options.

REQUEST ADDITIONAL INFORMATION



GET SAMPLE



SAVE TO LIST ▾



CHECK FOR TOOLING



FIND SIMILAR PRODUCTS



Feedback

DOCUMENTATION

FEATURES

PRODUCT COMPLIANCE

Product Drawings

CABLE, RADIATION-CROSSLINKED, POLYALKENE-INSULATED, TWO
CONDUCTOR, SHIELDED, JACKETED, LIGHTWEIGHT, GENERAL PURPOSEPDF **(TIFF AVAILABLE)**

English

Customers Also Bought


SIGNAL RELAYS




BOX MOUNT D-SUB CONNECTORS



BREAKOUTS/TRANSITIONS

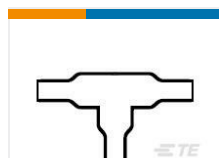

HEAT SHRINK BOOTS

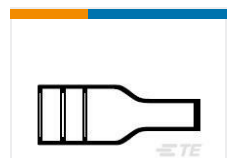

V23079G1008B301 V23079G1008B301	AMPLIMITE, ASY, RCPT, STD, 109, 5, KIT 205563-3	301A022-4/86-0 301A022-4/86-0	202D142-3/86-0 202D142-3/86-0