

[Find by Feature](#)
[Browse by Category](#)
[Share](#)

Enter part number or keyword

[Search Results \(0\)](#)
[Search Options](#)

Select a product type to narrow your search:

Terminal ▼

Results with your selections: --

Blade size [mm] ▼

Terminal family ▼

Material ▼

Plating ▼

Gender ▼

Sealed ▼

Inside Ring Diameter [mm] ▼

Outside Ring Diameter [mm] ▼


Minimum Cable Core Cross Section [mm²] ▼

Maximum Cable Core Cross Section [mm²] ▼

Minimum Cable Diameter [mm] ▼

Maximum Cable Diameter [mm] ▼

**Female Metri-Pack 280 Tin Plated Terminal,
Cable Range 0.50 - 0.35 mm², Cable
Insulation Range 2.19 - 1.47 mm
Part #12110644**

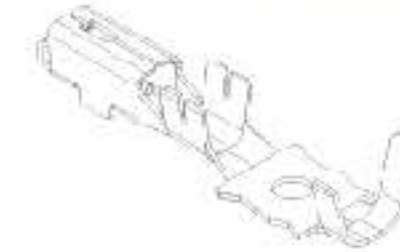

Question about this product?

[Attributes](#)
[Documents \(6\)](#)

Part #:	12110644
Description:	Female Metri-Pack 280 Tin Plated Terminal, Cable Range 0.50 - 0.35 mm ² , Cable Insulation Range 2.19 - 1.47 mm
Product Type:	Terminal
Status:	Active
Blade size [mm]:	2.8
Terminal family:	Metri-Pack
Series:	280
Gender:	Female
Sealed:	Unsealed
Plating:	Tin
Minimum Cable Core Cross Section [mm²]:	0.35
Maximum Cable Core Cross Section [mm²]:	0.50
Minimum Cable Diameter [mm]:	1.47
Maximum Cable Diameter [mm]:	2.19
Current range [A]:	30
Temperature range [°C]:	-40 to 125

Certain products listed on this website may be subject to restricted usage or distribution or may not be available. For additional information, please contact your local sales office.