

# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



M23, Cable connector, CA, angled, shielded: yes, Screw locking, No. of pos.: 6, Direction of rotation: Standard, type of contact: Socket, Solder connection, cable diameter range: 3 mm ... 14.5 mm, coding:N, Alternative product in accordance with RoHS II without Exemption 6c (Pb <0.1%) item no.: 1243464

## Your advantages

- Angled cable outlet for confined spaces
- Can be adapted to various applications, thanks to adjustable cable outlet direction
- Safe use in the field, thanks to high degree of protection
- Connector for flexible on-site assembly
- Consistent EMC protection for reliable transmission of signals
- Solder connection: proven connection technology for various litz wires

## Commercial Data

Item number	1619343
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to Order (non-returnable)
Sales Key	A12
Product Key	ABRBFB
Catalog Page	Page 92 (C-2-2019)
GTIN	4046356825016
Weight per Piece (including packing)	195.2 g
Weight per Piece (excluding packing)	195.2 g
Customs tariff number	85366990
Country of origin	DE

# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

## Technical Data

### Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

### Connector

#### Connection 1

Head design	Socket
-------------	--------

#### Insulating body

Coding	N
Insulation body material	PBT
Contact material	CuZn
Contact surface material	Ni/Au
Insertion/withdrawal cycles	100
Connection method	Solder connection
Contact type	Socket
Application	Signal
Number of positions	6
Direction of rotation	Standard
Connection profile	6
Rated voltage	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3
Contact diameter	2 mm
Litz wire cross-section	2.5 mm <sup>2</sup>
Nominal current per signal contact	20 A

### Signal contacts

### Signal contacts max.

#### Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	Screw locking
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

#### Seal

External cable diameter	3 mm ... 14.5 mm
Seal material	NBR

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

# Cable connector - CA-06S1N12T0DN


1619343

<https://www.phoenixcontact.com/us/products/1619343>



## Drawings

Schematic diagram

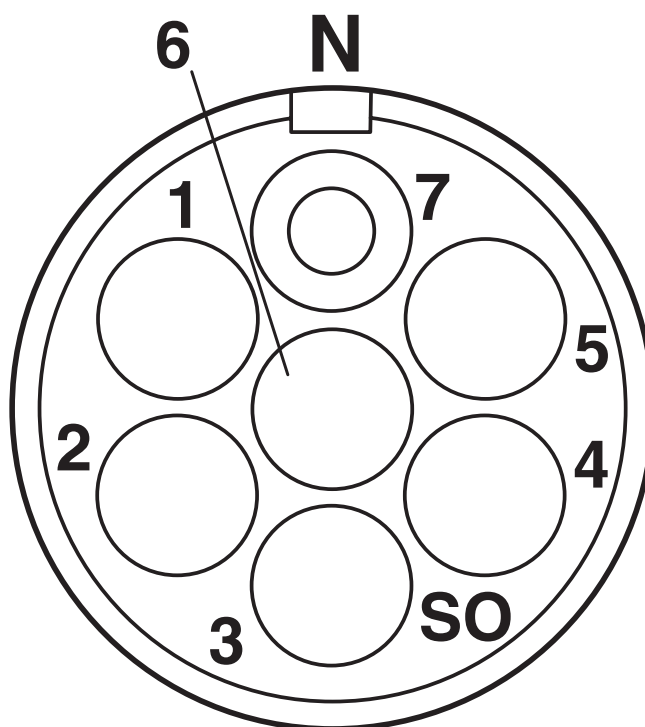


# Cable connector - CA-06S1N12T0DN

1619343

<https://www.phoenixcontact.com/us/products/1619343>



Dimensional drawing

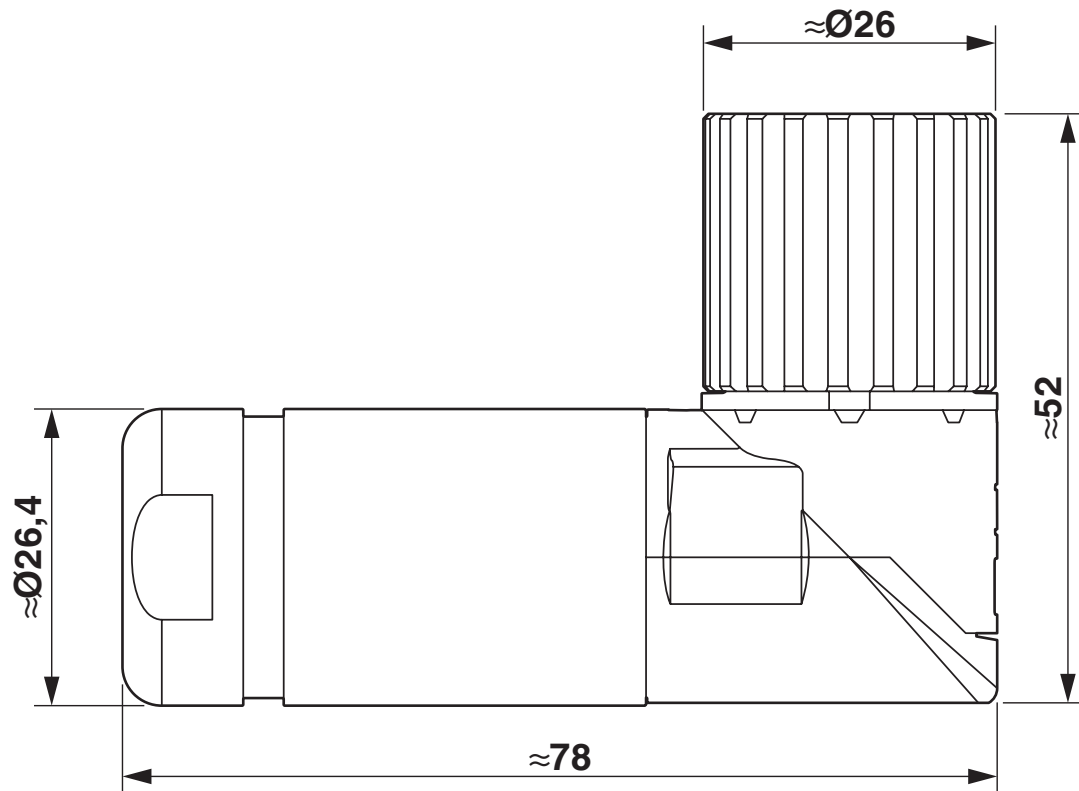

# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

## Approvals

 <b>cUL Recognized</b> Approval ID: E335019-20141210				
	Nominal Voltage $U_N$	Nominal Current $I_N$	Cross Section AWG	Cross Section $\text{mm}^2$
	48 V	10 A	- 14	-

 <b>UL Recognized</b> Approval ID: E335019-20141210				
	Nominal Voltage $U_N$	Nominal Current $I_N$	Cross Section AWG	Cross Section $\text{mm}^2$
	48 V	20 A	- 14	-

<b>cULus Recognized</b>				
-------------------------	--	--	--	--

# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

## Classifications

### ECLASS

ECLASS-9.0	27440102
ECLASS-10.0.1	27440102
ECLASS-11.0	27440102

### ETIM

ETIM 8.0	EC002635
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

# Cable connector - CA-06S1N12T0DN

1619343

<https://www.phoenixcontact.com/us/products/1619343>



## Accessories

### Torque screwdriver

Torque screwdriver - SF-Z0028 - 1607456

<https://www.phoenixcontact.com/us/products/1607456>

Torque screwdriver, series: RC



---

### Hook wrench

Hook wrench - SF-Z0027 - 1607455

<https://www.phoenixcontact.com/us/products/1607455>

Hook wrench, series: RC





# Cable connector - CA-06S1N12T0DN

1619343

<https://www.phoenixcontact.com/us/products/1619343>



## Protective cap

Protective cap - RC-Z2058 - 1604223

<https://www.phoenixcontact.com/us/products/1604223>

Plastic protection cap for connectors with M23 knurled nut



---

## Plastic anti-static dust protection cap

Plastic anti-static dust protection cap - RC-Z2468 - 1611796

<https://www.phoenixcontact.com/us/products/1611796>

Plastic protection cap, antistatic, for connectors with M23 knurled nut



# Cable connector - CA-06S1N12T0DN

1619343

<https://www.phoenixcontact.com/us/products/1619343>



## Color-coding

Color-coding - RF-Z0014 - 1620588

<https://www.phoenixcontact.com/us/products/1620588>

Color-coding, color: green



---

## Color-coding

Color-coding - RF-Z0015 - 1620592

<https://www.phoenixcontact.com/us/products/1620592>

Color-coding, color: orange



# Cable connector - CA-06S1N12T0DN



1619343

<https://www.phoenixcontact.com/us/products/1619343>

## Color-coding

Color-coding - RF-Z0016 - 1620593

<https://www.phoenixcontact.com/us/products/1620593>

Color-coding, color: black



---

Phoenix Contact 2022 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

[info@phoenixcon.com](mailto:info@phoenixcon.com)