


Data Sheet | Item Number: 286-895


Switching module; with changeover rocker switch; Switching voltage: 250 VAC;

Switching current: 6 A; gray

<https://www.wago.com/286-895>

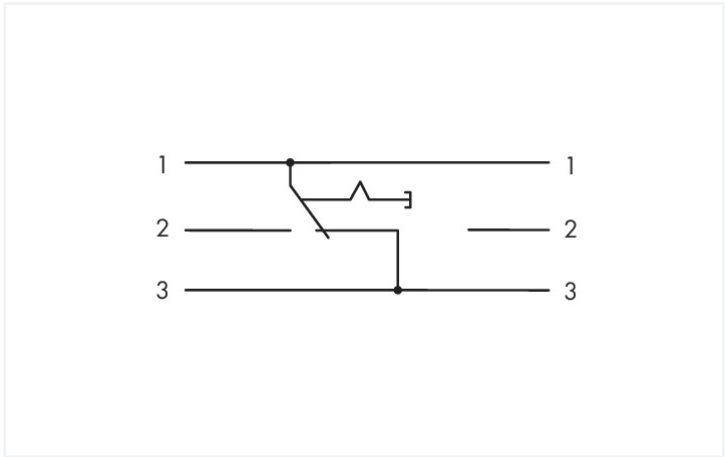

Color: ■ gray

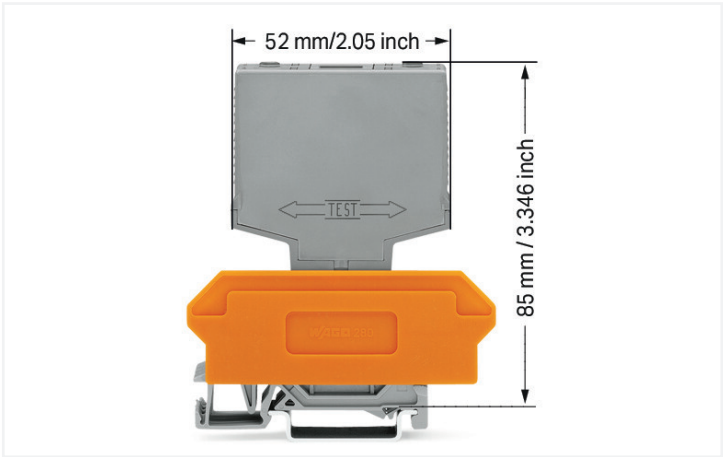

Electrical data	
Switching current (resistive) max.	6 A
Switching voltage (max.)	AC 250 V; DC 24 V
Contact gap	≥ 3 mm
Electrical life (NO; resistive load; 23 °C)	50 x 10 ³ switching operations

Physical data	
Width	15 mm / 0.591 inches
Height from upper-edge of DIN-rail	85 mm / 3.346 inches
Depth	52 mm / 2.047 inches



Mechanical data	
Mounting type	Pluggable module for receptacle terminal blocks
Housing design	Plug for carrier terminal blocks

Material data	
Color	gray
Fire load	4.165 MJ
Weight	20.5 g

Environmental requirements	
Ambient temperature (operation)	-20 ... +40 °C
Relative humidity	5 ... 85 % (no condensation permissible)
Operating altitude (max.)	2000 m

Commercial data	
Product Group	6 (INTERFACE ELECTRONIC)
eCl@ss 10.0	27-37-16-01
eCl@ss 9.0	27-37-16-01
ETIM 8.0	EC001437
ETIM 7.0	EC001437
PU (SPU)	15 (1) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454399801
Customs tariff number	85365080900

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Approvals / Certificates	
General approvals	



Approval	Standard	Certificate Name
EAC Brjansker Zertifizierungs- stelle	TP TC 004/2011	EAC RU C-DE.AM02. B.00122/19

Downloads
Environmental Product Compliance



Compliance Search			
Environmental Product Compliance 286-895			

Documentation			
Bid Text		Instruction Leaflet	
286-895	19.02.2019	xml 2.98 KB	
286-895	01.04.2015	doc 24.00 KB	
		pdf 1246.19 KB	

CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 286-895	WSCAD Universe 286-895
	ZUKEN Portal 286-895

1 Compatible Products
1.1 Optional Accessories
1.1.1 Marking
1.1.1.1 Marker



[Item No.: 209-701](#)
WSB marking card; as card; not stretchable; plain; snap-on type; white

1.1.2 Terminal blocks
1.1.2.1 Terminal block for pluggable modules



[Item No.: 280-619](#)
Terminal block for pluggable modules; 6-pole; with 2-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; CAGE CLAMP®; 2,50 mm²; gray



[Item No.: 280-763](#)
Terminal block for pluggable modules; 6-pole; with 4-conductor terminal blocks; with marker carrier; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; CAGE CLAMP®; 2,50 mm²; gray



[Item No.: 280-609](#)
Terminal block for pluggable modules; 6-pole; with 4-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; CAGE CLAMP®; 2,50 mm²; gray

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com