




**Part Number :** [982670349](#)

**Product Description :** 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 229.00mm Cable Length, Tin (Sn) Plating, 18 Circuits

**Series Number :** 98267

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

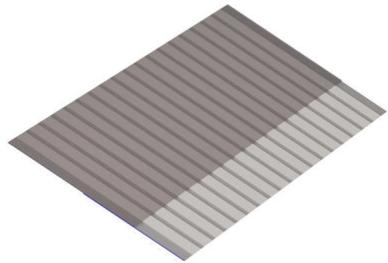

## Documents & Resources

### Drawings

[982670349\\_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[PS-98267-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |   |
|--------------------|---|
| GADSL/IMDS         | Not Relevant                                    |
| China RoHS         | ⓘ<br>per SJ/T 11365-2006                        |
| EU ELV             | Not Relevant                                    |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21              |
| REACH SVHC         | Not Contained per D(2025)4165-DC (25 June 2025) |
| EU RoHS            | Compliant per EU 2015/863                       |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

|              |   |
|--------------|---|
| Status       | Active  |
| Category     | Flat-Flexible Cable (FFC)   |
| Series       | 98267   |
| Description  | 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 229.00mm Cable Length, Tin (Sn) Plating, 18 Circuits |
| Comments     | Contacts on the same side, Type A   |
| Product Name | Premo-Flex FFC Jumper   |
| UPC          | 756054773482  |

### Electrical

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 1.2A   |
| Voltage - Maximum             | 60V AC |

### Physical

|                           |                |
|---------------------------|----------------|
| Cable Length              | 229.00mm       |
| Circuits (Loaded)         | 18             |
| Contact Layout Type       | A (same side)  |
| Design Feature            | Extra-Flexible |
| Material - Plating Mating | Tin            |
| Net Weight                | 3.025/g        |
| Packaging Type            | Bag            |
| Pitch - Mating Interface  | 1.00mm         |

|                               |                 |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C  |
| Termination Style             | FFC Connector   |
| Wire/Cable Type               | Flat Flex Cable |
| Wire Size (AWG)               | N/A             |

## Mates With / Use With

### Mates with Part(s)

| Description   | Part Number                      |
|---|----------------------------------|
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 18 Circuits, Tin-Bismuth Plating        | <a href="#"><u>522711879</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 18 Circuits, Tin-Bismuth Plating                           | <a href="#"><u>526101871</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, 18 Circuits                                     | <a href="#"><u>528081870</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 18 Circuits | <a href="#"><u>528081871</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Top Contact, 2.70mm Height, 18 Circuits, Tin-Bismuth Plating           | <a href="#"><u>522071885</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 18 Circuits                                 | <a href="#"><u>527931870</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Vertical, Surface Mount Compatible, Non-ZIF, Kinked PC Tails, 18 Circuits                           | <a href="#"><u>528061810</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC  | <a href="#"><u>528071810</u></a> |

|  |                  |
|--|------------------|
| Connector, Right-Angle, Non-ZIF, Top Contact Style Receptacle, 18 Circuits                                     |                  |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Bottom Contact Style, 18 Circuits | <u>528521870</u> |

---

This document was generated on Sep 11, 2025