

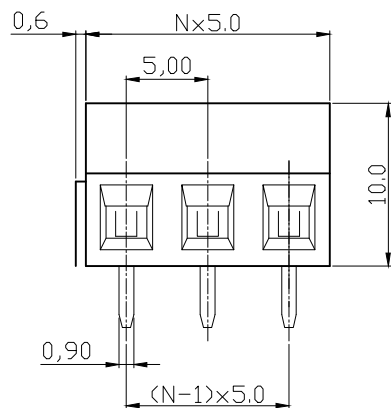


	1	2	3	4	5	6	7	
A								A
B								B
C								C
D								D
E								E
F								F
G								G
H								H
	1	2	3	4	5	6	7	SV1501

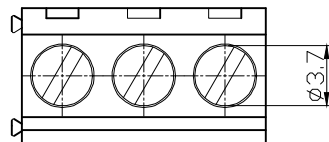

N= NUMBER OF CONCATS

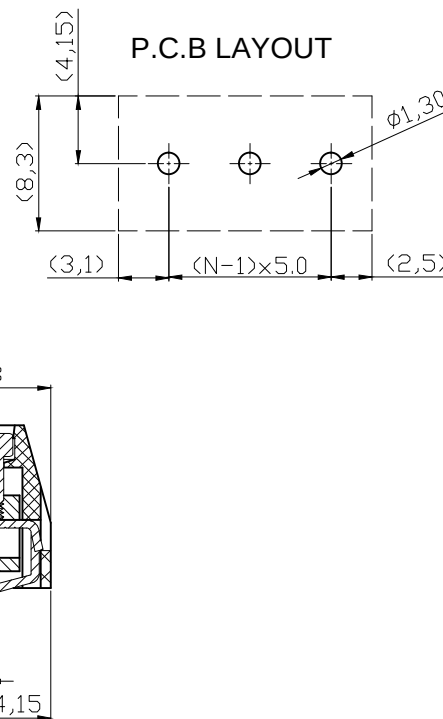

Material

- 1.Terminal body
(metal housing): Brass(CuZn)
- 2.Terminal screw:Steel Zinc plating"-slot type
- 3.Contacts: Brass
- 4.Surface of solder tail: Tin plated
5. Insulator (housing): Thermoplastic (UL94V-0),Green

Electrical UL / VDE

- 1.Voltage rating: 300VAC/250VAC
- 2.Current rating: 10A/10A
- 3.Wire range: 0.5-1.5mm²
- 4.Solid wire(AWG): 16-26
- 5.Stranded wire(AWG): 16-26
- 6.Torque: 3.5Lb-In/0.4N.m
- 7.Screw:M2.5
- 8.Wire strip length:5-6mm
- 9.Withstanding Voltage: 1.6KV/2KV
- 10.Operating temperature: -30°C to +105°C
- 11.Soldering temperature: 250°C±10°C/5 Sec
- 12.Safety Approval:  

RoHS compliant

Unit: mm



File No.: E349947

Scale	1:1					Date	Name	Customer-No.
TOLERANCE						Drawn	10.09.2008	N.Schulz
X.	±0.50					Approved	18.04.2016	Joanna
X.X	±0.30							
X.XX	±0.10	③	Add UL	18.04.2016	Joanna			
DIM	TOL	②	Update	27.05.2009	Dean			
X.°	±1°							
X.X°	±X°	①	Drawn	10.09.2008	N.Schulz			
Angle	TOL	Id.	Modification	Date	Name			

ASSMANN
WSW components

ASSMANN WSW-No.
A-TB500-TOxx

Drawing-No.
ASS 2783 CO rev03

Replace Sheet