




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 1/4 Round Swage Spacers

1/4 ROUND SWAGE SPACERS

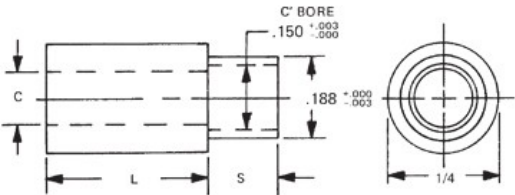

Qty1 *

Qty2

Qty3

☐	15311	5/32
☐	1532	3/16
☐	1532T	7/32
☐	1533	1/4
☐	1533T	9/32
☐	1534	5/16
☐	1534T	11/32
☐	1535	3/8
☐	1535T	13/32
☐	1536	7/16
☐	1536T	15/32
☒	1537	1/2
☐	1537T	17/32
☐	1538	9/16

Shank *

Select	S	0.003-0.003	P
☐	A	.075	1/32
☒	B	.105	1/16
☐	C	.135	3/32
☐	D	.165	1/8
☐	E	.230	3/16
☐	F	.290	1/4

Clearance Hole *

Select	Code	+0.010-.000
☐	2	.090
☐	3	.101
☐	4	.115
☒	6	.140

Material *

Select	Code	Material	RoHS
☒	AL	Aluminum	YES
☐	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES

[Home](#) [Previous](#) [Next](#)

[Related Metric](#)

Ordering Code				
xxxxx	x	x	xx	x
Length		Clearance Hole		Finish
	Shank		Material	

PART: 1537 B 6 AL ?

Red ?'s show missing selections. [Help](#)

[Material Specifications](#)

[Ordering non-standard items](#)

Add to Cart

Swage Tool		
Punch	Anvil	Length
P-4	AR-22	3/32-3/16
P-4	AR-23	7/32-7/16
P-4	AR-24	15/32-11/16
P-4	AR-25	23/32-1"

1/4 Round Swage Spacers

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite*
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc