


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2017/3/30

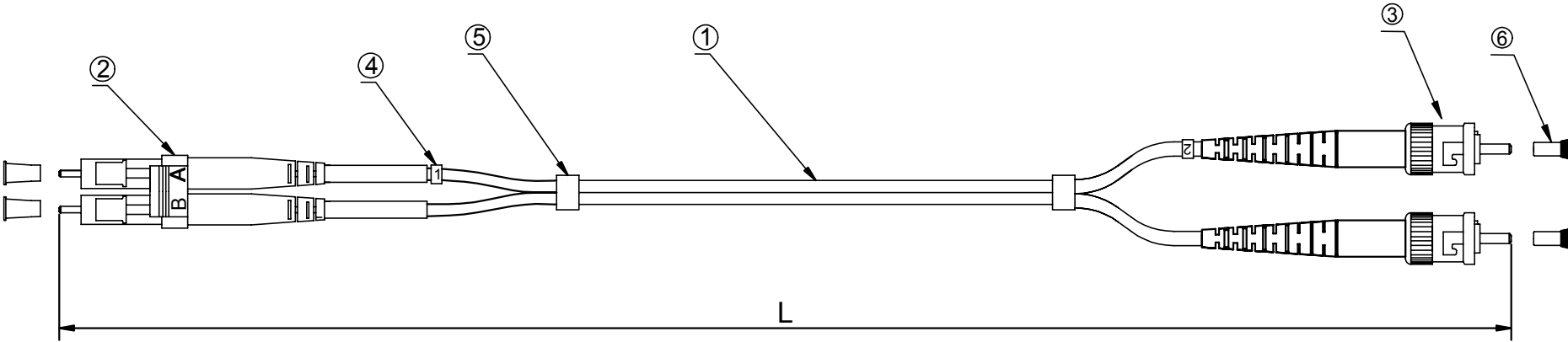

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
913S-2-5-00100-PL	671-457-A	1000±100	Yellow
913S-2-5-00200-PL	671-457-B	2000±100	Yellow
913S-2-5-00300-PL	671-457-C	3000±100	Yellow
913S-2-5-00500-PL	671-457-D	5000±100	Yellow
913S-2-5-00700-PL	671-457-E	7000±100	Yellow
913S-2-5-01000-PL	671-457-F	10000±100	Yellow
913S-2-5-01500-PL	671-457-G	15000±100	Yellow
913S-2-5-02000-PL	671-457-H	20000±100	Yellow
913S-2-5-02500-PL	671-457-I	25000±100	Yellow

NOTES:
Insertion loss < 0.3 dB
Return loss > 50 dB

CnC Tech, LLC

Industrial Cable and Connector Technology

UNIT

mm

unless otherwise stated

Tolerances

mmXXX.XX ±0.3

XX.XX ±0.2

X.XX ±0.1

angular

±2°

TITLE

Patch Cord, LC-ST,SM-9/125 G652D, Duplex, OFNP, yellow, 2.0mm, xxM

P/N

above

DRAWN BY

Customer P/N

913S-2-5-0xxxx-PL

CHECK BY

SIZE

A4

SCALE

Free

PAGE

1/1

APPROVAL BY

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	ST SM Connector (Metal housing Yellow boot)
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, OFNP, Optical Fiber Cable(Yellow)
No.	Description

Downloaded from Arrow.com