


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350729712](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: MP-Lock™ Quick Disconnect, Female, for 18-22 AWG (0.80-0.33mm²), Metal Strip, Tab 6.35 x 1.00mm, Pre-Tin Plated

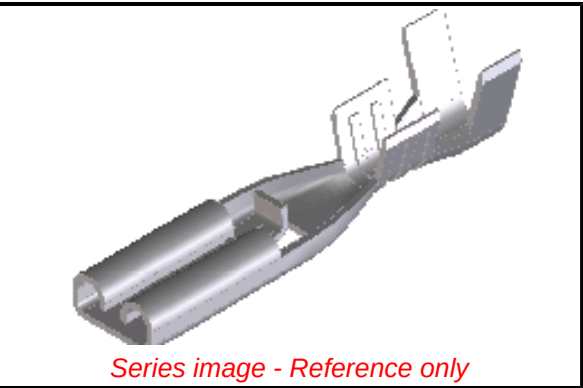

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-35072-001-001 \(PDF\)](#)

General
Product Family Quick Disconnects
Series [35072](#)
Crimp Quality Equipment Yes
Insulated No
Overview [Standard Quick-Disconnect Terminals](#)
Product Name MP-Lock™
Type Quick Disconnect
UPC 800753315730

Physical
Barrel Type Open
Gender Female
Glow-Wire Compliant No
Insulation None
Lock to Mating Part Yes
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.813/g
Orientation Straight
Packaging Type Reel
Plating min - Mating 0.813µm
Plating min - Termination 0.813µm
Polarized to Mating Part Yes
Tab Thickness 1.00mm
Tab Width 6.35mm
Temperature Range - Operating -40°C to +105°C
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.50-3.20mm max.
Wire Size AWG 18, 20, 22

Electrical
Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers
Packaging Specification PK-35072-001-001
Sales Drawing SD-35072-9702

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Low-Halogen

Need more information on product environmental compliance?
Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[35072 Series](#)

Use With
[35196](#) , [35959](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION