

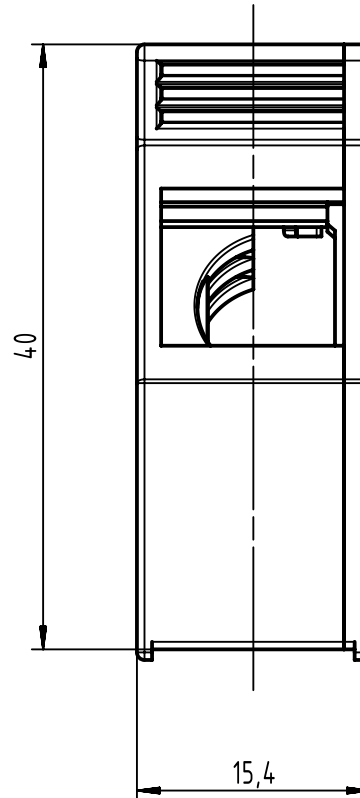
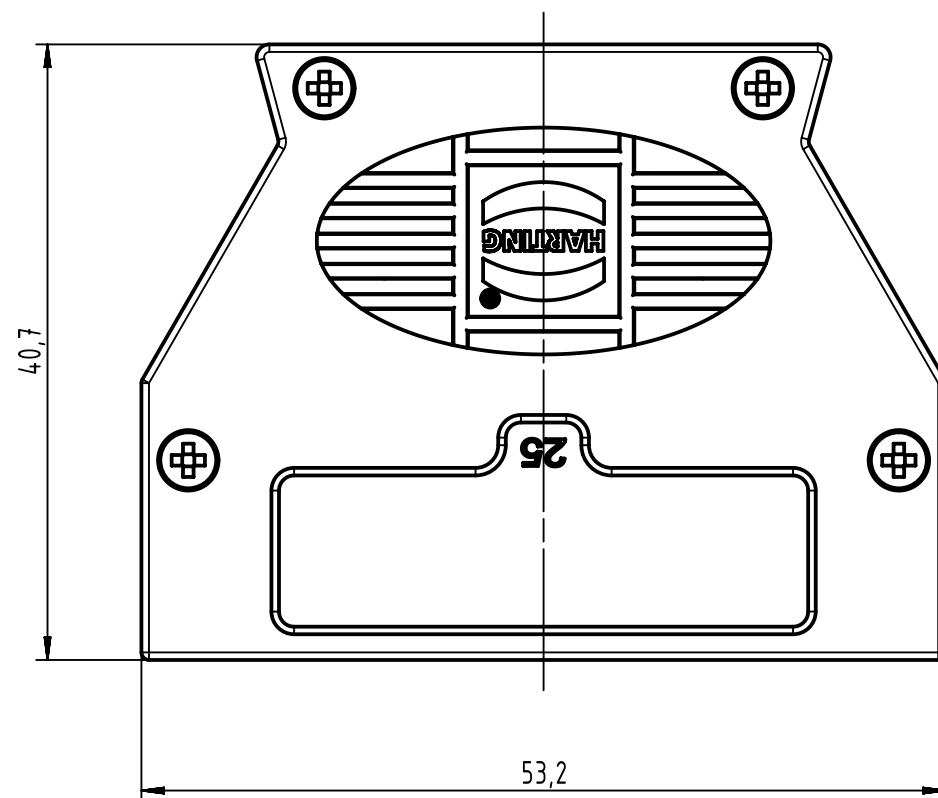


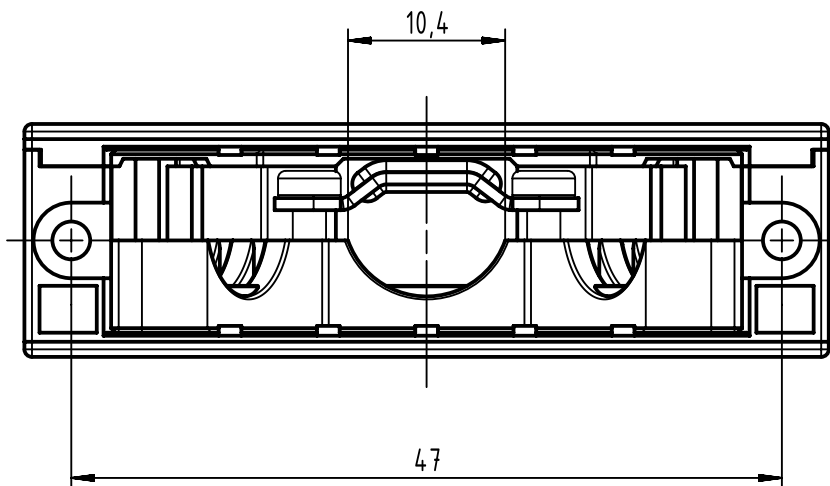

Cable diameter between 4 and 9mm, 10mm max. with longer cable clamp screws(0967 000 9946)
Cable clamp screws max. torque=0,3Nm
Cover screws max. torque=0,15Nm for 0967 025 0453
Cover screws max. torque=0,25Nm for 0967 025 0452

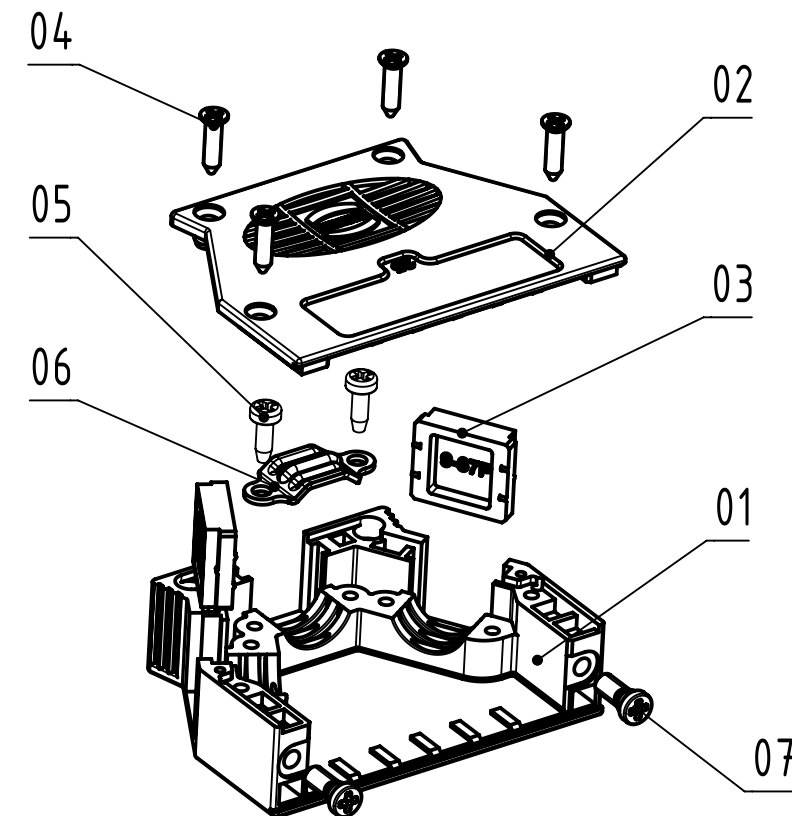

Content D-Sub hood				Spare parts (MOQ100)	
Pos.	Quantity	Description	Part Number	Quantity	
01	1	Housing:			
		either thermoplastic metallized housing (for 0967 025 0453)			
		or thermoplastic black housing (for 0967 025 0452)			
02	1	Cover:			
		either thermoplastic metallized cover (for 0967 025 0453)			
		or thermoplastic black cover (for 0967 025 0452)			
03	2	Blank piece:			
		either thermoplastic metallized blank piece (for 0967 025 0453)	0967 003 6011	1	
		or thermoplastic black blank piece (for 0967 025 0452)			
04	4	Screws for cover			
05	2	Screws for cable clamp x6,5mm	0967 000 9944	1	
		Screws for cable clamp x8,5mm (optional)	0967 000 9946	1	
06	1	Cable clamp	0967 000 9943	1	
07	2	Locking bolt	0967 003 6014	1	

		All Dimensions in mm Original Size DIN A3		Scale 2:1	Free size tol.		Ref.		
							Sub.		
		All rights reserved		Created by ZENGDO	Inspected by LUOK	Standardisation HOFFMANN	Date 2019-11-06	State Final Release	
		Department EL PD							
HARTING Electronics GmbH D-32339 Espelkamp		Title D-Sub 25-pole plastic top and side entry hood						Doc-Key / ECM-Nr. 100673462/UGD/009/B 500000160261	
		Type TB	Number 0967025045Y					Rev. B	Page 1/1

0967 025 0453	D-Sub 25-pole thermoplastic metallized top and side entry hood for spring or slide locking
0967 025 0452	D-Sub 25-pole thermoplastic black top and side entry hood for spring or slide locking
Part number	Description

1	2	3	4
---	---	---	---

5	6	7	8
---	---	---	---