

# ICC20 Jam-Nut Receptacle

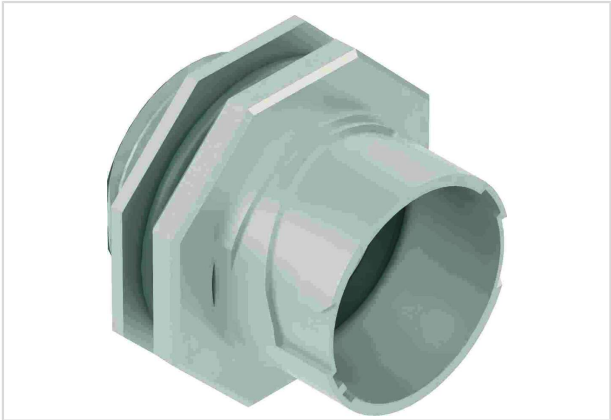


Image is for illustration purposes only. Please refer to product description.

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| Part number        | 19 59 120 2020                                                                        |
| Specification      | ICC20 Jam-Nut Receptacle                                                              |
| HARTING eCatalogue | <a href="https://b2b.harting.com/19591202020">https://b2b.harting.com/19591202020</a> |

## Identification

|                             |                                             |
|-----------------------------|---------------------------------------------|
| Category                    | Connectors                                  |
| Series                      | HARTING ICC                                 |
| Type of hood/housing        | Bulkhead mounted housing                    |
| Description of hood/housing | Straight<br>Rear mounting<br>incl. lock nut |

## Version

|              |                                                  |
|--------------|--------------------------------------------------|
| Size         | 20                                               |
| Locking type | Bayonet locking                                  |
| Details      | Please order backshell or fixing nut separately. |

## Technical characteristics

|                                        |                 |
|----------------------------------------|-----------------|
| Tightening torque                      | 15 Nm Lock nut  |
| Limiting temperature                   | -40 ... +125 °C |
| Number of relockings                   | ≥500            |
| Degree of protection acc. to IEC 60529 | IP67<br>IPX9    |

## Material properties

|                         |               |
|-------------------------|---------------|
| Material (hood/housing) | Zinc die-cast |
| Surface (hood/housing)  | Nickel plated |
| Material (seal)         | EPDM          |
| Colour (seal)           | Black         |



**Pushing Performance**  
Since 1945

## Material properties

|                                      |               |
|--------------------------------------|---------------|
| RoHS                                 | compliant     |
| ELV status                           | compliant     |
| China RoHS                           | e             |
| REACH Annex XVII substances          | Not contained |
| REACH ANNEX XIV substances           | Not contained |
| REACH SVHC substances                | Not contained |
| California Proposition 65 substances | Not contained |

## Specifications and approvals

|                |             |
|----------------|-------------|
| Specifications | IEC 61984   |
|                | IEC 60664-1 |
| CE             | Yes         |

## Commercial data

|                                |                                        |
|--------------------------------|----------------------------------------|
| Packaging size                 | 1                                      |
| Net weight                     | 90.5 g                                 |
| European customs tariff number | 85389099                               |
| GTIN                           | 5713140400566                          |
| eCl@ss                         | 27440224 Shell for circular connectors |