



Pushing Performance  
Since 1945

# SEK CAB FLAT STD HF AWG28/7 40P 30,48m

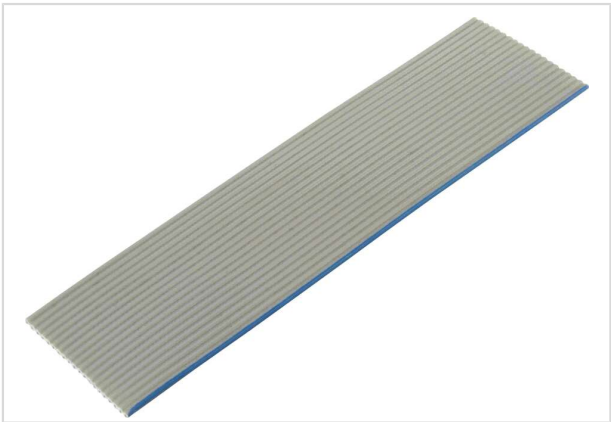


Image is for illustration purposes only. Please refer to product description.

|                    |                                                                                     |
|--------------------|-------------------------------------------------------------------------------------|
| Part number        | 09 18 040 7001 900                                                                  |
| Specification      | SEK CAB FLAT STD HF AWG28/7 40P 30,48m                                              |
| HARTING eCatalogue | <a href="https://harting.com/09180407001900">https://harting.com/09180407001900</a> |

## Identification

|               |                     |
|---------------|---------------------|
| Category      | System cabling      |
| Element       | Bulk cables         |
| Specification | Not assembled       |
| Type of cable | Copper cable (flat) |

## Version

|                 |          |
|-----------------|----------|
| Cable length    | 30.48 m  |
| Number of cores | 40       |
| Core structure  | AWG 28/7 |

## Technical characteristics

|                      |                                                  |
|----------------------|--------------------------------------------------|
| Impedance            | 110 Ω                                            |
| Limiting temperature | -40 ... +105 °C unmoved<br>-20 ... +105 °C moved |

## Material properties

|                             |                 |
|-----------------------------|-----------------|
| Material (cable)            | Non-halogenated |
| RoHS                        | compliant       |
| ELV status                  | compliant       |
| China RoHS                  | e               |
| REACH Annex XVII substances | Not contained   |
| REACH ANNEX XIV substances  | Not contained   |
| REACH SVHC substances       | Not contained   |



Pushing Performance  
Since 1945

Material properties

|                                      |               |
|--------------------------------------|---------------|
| California Proposition 65 substances | Not contained |
|--------------------------------------|---------------|

Specifications and approvals

|                |         |
|----------------|---------|
| Specifications | UL 1581 |
|                | UL 758  |
| Approvals      | CE      |

Commercial data

|                                |                                                |
|--------------------------------|------------------------------------------------|
| Packaging size                 | 1                                              |
| Net weight                     | 0.1 g                                          |
| Net weight                     | 73 g/m                                         |
| Country of origin              | USA                                            |
| European customs tariff number | 85444993                                       |
| GTIN                           | 5713140025172                                  |
| eCl@ss                         | 27061801 Data and communication cable (copper) |
| ETIM                           | EC003249                                       |
| UNSPSC 24.0                    | 26121609                                       |