


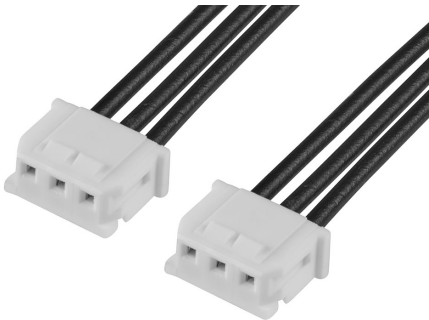

**Part Number :** [2196781033](#)  
**Product Description :** Micro-Latch-to-Micro-Latch Off-the-Shelf (OTS) Cable Assembly, 2.00mm Pitch, Tin (Sn) Plating, 300.00mm Length, 3 Circuits, Natural  
**Series Number :** 219678  
**Status :** Active  
**Product Category :** Power and Signal Cable Assemblies



Documents & Resources

Drawings  
[2196781033\\_sd.pdf](#)

Product Environment Compliance

Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                    |
| REACH SVHC         | Not Contained per D(2024)7663-DC (21 Jan 2025)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

---

## Part Details

### General

|                        |                                                                                                                                     |
|------------------------|-------------------------------------------------------------------------------------------------------------------------------------|
| Status                 | Active                                                                                                                              |
| Category               | Power and Signal Cable Assemblies                                                                                                   |
| Series                 | 219678                                                                                                                              |
| Description            | Micro-Latch-to-Micro-Latch Off-the-Shelf (OTS) Cable Assembly, 2.00mm Pitch, Tin (Sn) Plating, 300.00mm Length, 3 Circuits, Natural |
| Application            | Signal, Wire-to-Board                                                                                                               |
| Assembly Configuration | Dual Ended Connectors                                                                                                               |
| Connector to Connector | Micro-Latch-to-Micro-Latch                                                                                                          |
| Product Name           | Micro-Latch                                                                                                                         |
| Type                   | Discrete Wire Assembly                                                                                                              |
| UPC                    | 195842859678                                                                                                                        |

### Electrical

|                               |                  |
|-------------------------------|------------------|
| Current - Maximum per Contact | 2.5A             |
| Voltage - Maximum             | 250V AC (RMS)/DC |

### Physical

|                                |                 |
|--------------------------------|-----------------|
| Cable Length                   | 300.00mm        |
| Circuits (Loaded)              | 3               |
| Circuits (maximum)             | 3               |
| Color - Resin                  | Natural         |
| Gender                         | Female-Female   |
| Lock to Mating Part            | Yes             |
| Material - Metal               | Phosphor Bronze |
| Material - Plating Mating      | Tin             |
| Material - Plating Termination | Tin             |
| Material - Resin               | Polyester       |
| Net Weight                     | 4.106/g         |
| Number of Rows                 | 1               |
| Packaging Type                 | Bag             |
| Pitch - Mating Interface       | 2.00mm          |

|                             |                      |
|-----------------------------|----------------------|
| Plating min - Mating        | 0.900µm              |
| Plating min - Termination   | 0.900µm              |
| Single Ended                | No                   |
| Termination Interface Style | Crimp or Compression |
| Wire/Cable Type             | UL 10002             |
| Wire Size (AWG)             | 22                   |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                | Part Number  |
|--------------------------------------------|--------------|
| Micro-Latch Vertical Single Row Headers    | <u>53253</u> |
| Micro-Latch Right-Angle Single Row Headers | <u>53254</u> |

---

This document was generated on Apr 26, 2025