



» COMe-mTT10 «

COMe-mTT10
w/ mSD card slot

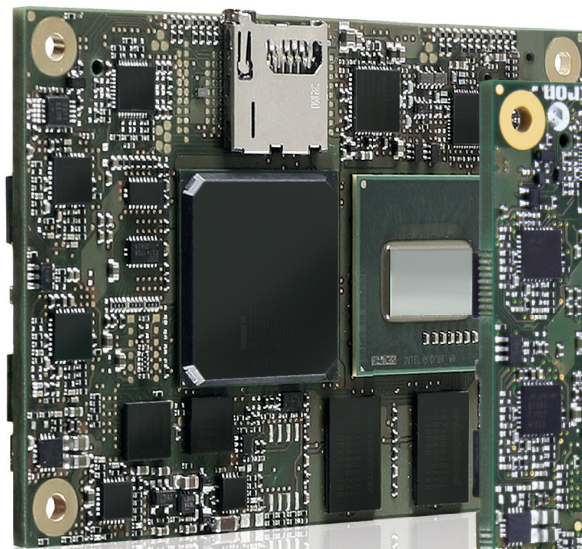

COMe-mTT10
w/ SSD Flash onBoard

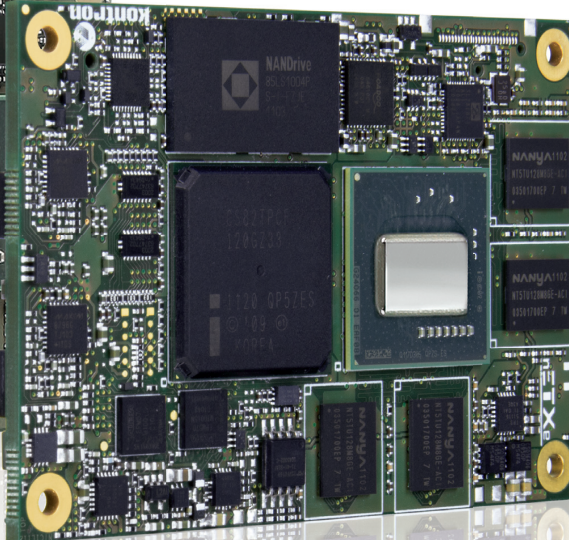

COM Express® mini Computer-on-Module designed for industrial temperature use

- » COM Express® mini pin-out Type 10
- » Designed for Industrial temperature range -40°C to +85°C (E2)
- » Variants for commercial temperature grade 0°C to 60°C
- » Intel® Atom™ processor E6xx @ 600 MHz up to 1.6 GHz

Technical Information

Processor	Intel® Atom™ E6xx/E6xxT (0.6 GHz + 1.0 GHz + 1.3 GHz + 1.6 GHz)
Cache	32 KB Instruction Cache + 24 KB L1 Cache, 512 KB L2 Cache
Chipset	Intel® Platform Controller Hub EG20T
Memory	onboard up to 2 GB DDR2-800
Hard Disk	Option 1: 2 x Serial ATA external supporting 3 GB/s plus 1 x micro SD card Slot on SDIO Option 2: 1 x Serial ATA external supporting 3 GB/s + 1 x Serial ATA onBoard E2 SSD Flash drive up to 8 GByte
USB	6 x USB 2.0 (boot) + 1x USB Client
PCI Express	4x PCI Express x1 Lanes, one for onboard PCH EG20T
Serial	2 x serial interface TTL
Ethernet	onBoard10/100/1000 Mbit LAN, MAC Chipset integrated
Ethernet Controller	Broadcom BCM54610, Phy
Interface	4Bit SDIO 2.0 interface shared with GPIO on COM Express® Connector
SPI / SM Bus Support	External Boot via SPI flash device / SM Bus Support yes
Audio Controller	Intel® High Definition Audio
Graphics Controller	Integrated 2D/3D Graphics Engine, Gfx Core 333/400 Mhz, shared VRAM Video Encode : MPEG4, H.263, H.264; Video Decode : MPEG2, MPEG4, VC1, WMV9, H.264
Graphics Memory	up to 352MB
Resolution	LVDS 18/24bit 1280x768@60Hz; SDVO 1920x1080@50Hz
Operating System	Windows® XP SP3, XPe, WES 7, CE, Linux, VxWorks, QNX
Power Consumption	Idle 4,7W - 5,3 W@12V
Power Supply	4.75V - 14V Wide Range Power Supply (optional 5V stand-by for ATX function); ACPI 3.0
Temperature/Humidity	Operation: COMe-mTTc10 0°C to +60°C, Storage: -30° to 85°C / Operation: 10% to 90%, Storage: 5% to 95% (non condensing) Operation: COMe-mTTi10 -40°C to +85°C, Storage: -40° to 85°C / Operation: 10% to 90%, Storage: 5% to 95% (non condensing)
Compliance	COM Express® mini, pin-out Type 10, 55mm x 84mm

Ordering Information

Article	Part-No.	Description
COMe-mTTi10 0.6 GHz 512/mSD	34003-5100-06-1	COMe-mTTi10 w/ Atom™ E620T (0.6 GHz), 512MB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.0 GHz 1GB/mSD	34003-1000-10-1	COMe-mTTi10 w/ Atom™ E640T (1.0 GHz), 1GB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.0 GHz 1GB/4GB SSD	34003-1040-10-1	nCOMe-mTTi10 w/ Atom™ E640T (1.0 GHz), 1GB DDR2 onboard, PCIe, SATA II, Ethernet, 4GB SATA SSD, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.3 GHz 1GB/mSD	34003-1000-13-1	COMe-mTTi10 w/ Atom™ E660T (1.3 GHz), 1GB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.3 GHz 1GB/4GB SSD	34003-1040-13-1	COMe-mTTi10 w/ Atom™ E660T (1.3 GHz), 1GB DDR2 onboard, PCIe, SATA II, Ethernet, 4GB SATA SSD, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.6 GHz 1GB/mSD	34003-1000-16-1	COMe-mTTi10 w/ Atom™ E680T (1.6 GHz), 1GB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot, ind. Temp grade -40°C to +85°C
COMe-mTTi10 1.6 GHz 1GB/4GB SSD	34003-1040-16-1	COMe-mTTi10 w/ Atom™ E680T (1.6 GHz), 1GB DDR2 onboard, PCIe, SATA II, Ethernet, 4GB SATA SSD, ind. Temp grade -40°C to +85°C
COMe-mTTc10 0.6 GHz 512/mSD	34004-5100-06-1	COMe-mTTc10 w/ Atom™ E620 (0.6 GHz), 512MB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot
COMe-mTTc10 1.0 GHz 512/mSD	34004-5100-10-1	COMe-mTTc10 w/ Atom™ E640 (1.0 GHz), 512MB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot
COMe-mTTc10 1.3 GHz 512/mSD	34004-5100-13-1	COMe-mTTc10 w/ Atom™ E660 (1.3 GHz), 512MB DDR2 onboard, PCIe, SATA, Ethernet, micro SD slot

CORPORATE OFFICES

Europe, Middle East & Africa

Oskar-von-Miller-Str. 1
85386 Eching/Munich
Germany
Tel.: +49 (0)8165/ 77 777
Fax: +49 (0)8165/ 77 279
info@kontron.com

North America

14118 Stowe Drive
Poway, CA 92064-7147
USA
Tel.: +1 888 294 4558
Fax: +1 858 677 0898
info@us.kontron.com

Asia Pacific

17 Building,Block #1,ABP.
188 Southern West 4th Ring Road
Beijing 100070, P.R.China
Tel.: + 86 10 63751188
Fax: + 86 10 83682438
info@kontron.cn

