


Data Sheet | Item Number: 216-424

Ferrule; Sleeve for 35 mm² / AWG 2; uninsulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 1/08.92; silver-colored

<https://www.wago.com/216-424>



Color: ■ silver-colored

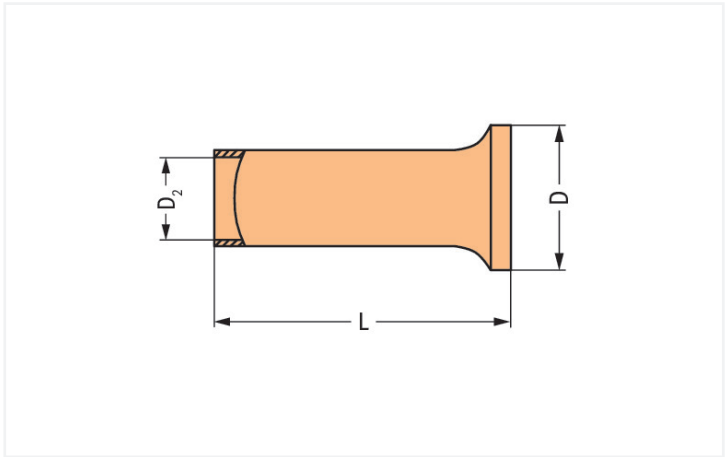

Dimensions in mm

Connection data	
Cross-section metric	35 mm²
Strip length	30 mm / 1.18 inches
Cross-section AWG	2 AWG

Physical data	
Total length	30 mm
Wall thickness crimp sleeve	0.2 mm
Diameter crimp sleeve inside	8.3 mm

Mechanical data	
Plastic collar	No

Material data	
Color	silver-colored
Fire load	0 MJ
Weight	1.5 g

Commercial data	
Product Group	2 (Terminal Block Accessories)
PU (SPU)	50 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821134190
Customs tariff number	85369010000




Product classification		
UNSPSC		39121405
eCl@ss 10.0		27-40-02-01
eCl@ss 9.0		27-40-02-01
ETIM 9.0		EC000005
ETIM 8.0		EC000005
ECCN		NO US CLASSIFICATION



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

## Downloads


### Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 216-424	

## Documentation

Bid Text			
216-424	19.02.2019	xml 2.77 KB	
216-424	11.09.2017	doc 24.00 KB	

## Installation Notes

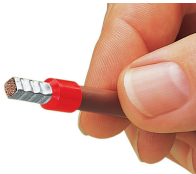

A perfect gas-tight crimp – both electrical-ly and mechanically reliable