

## Housing - HC-STA-D07-CHWS-1TGM20-PL-BK - 1419259

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Coupling housings D7, With single locking latch, Material: PA, Cable outlets: 1, straight, Height: 76 mm, Cable gland: with, Gland: no, 1x M20, Standard

As illustrated, but with M20 thread

RoHS

### Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 160108
GTIN	4055626160108
Weight per Piece (excluding packing)	30.000 g
Custom tariff number	85389099
Country of origin	China

### Technical data

#### Dimensions

Height	76 mm
Width	34.2 mm
Length	24.2 mm
External cable diameter	4 mm ... 10 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP66
Degree of protection of housing (NEMA)	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Housing - HC-STA-D07-CHWS-1TGM20-PL-BK - 1419259


Technical data

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Coupling housings
Color	black
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	with
Type of the screw connection	1x M20
Housing material	PA
Material lock	PA

Drawings

Dimensional drawing

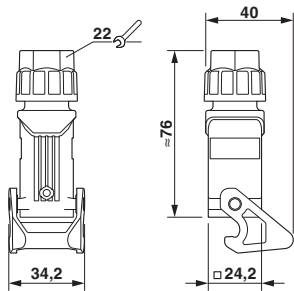

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

## Housing - HC-STA-D07-CHWS-1TGM20-PL-BK - 1419259

### Approvals

EAC



EAC-Zulassung

Phoenix Contact 2017 © - all rights reserved  
<http://www.phoenixcontact.com>