


H0,5/14 ZH OR SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

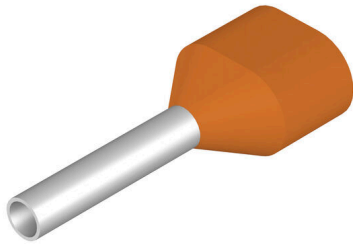

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, orange
Order No.	9004440000
Type	H0,5/14 ZH OR SV
GTIN (EAN)	4008190198473
Qty.	500 items
Packaging	Multipack bag

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.12 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, orange	Version	Twin wire-end ferrule
------------------------	-------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	1.4 mm	Contact surface length (L2)	8 mm
Collar width (B)	3 mm	Collar height (A)	5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	14.00 mm
Wire connection cross section AWG, max.	AWG 20	Metal sleeve thickness (S1)	0.15 mm
Stripping length	11 mm	Conductor cross-section	0.5 mm ²
Colour code	Weidmueller		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

