


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	30-00921	Wire, 5C BC, 20 AWG, UL20280, 300V, 80C, 6.2 mm, braided shield, FT2, TPU	1	

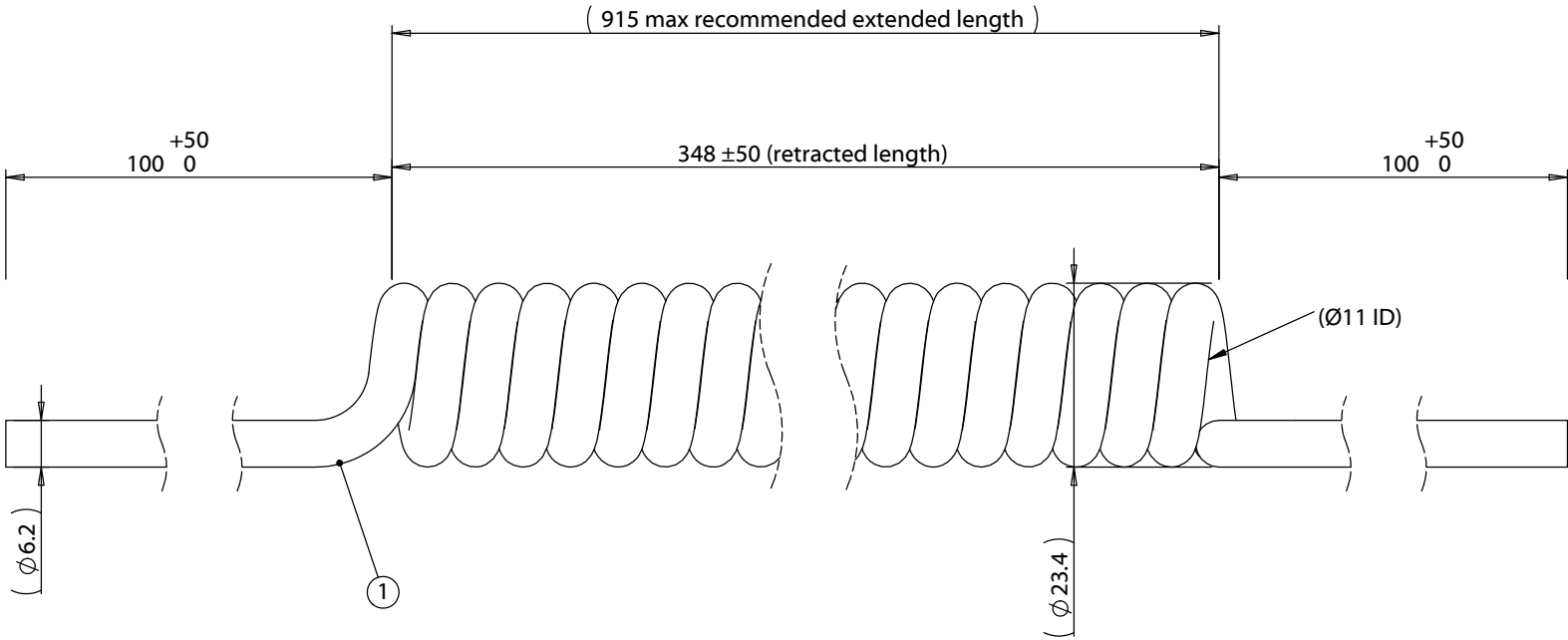

Notes:
Total wire length for resistance calculation: 3250 mm

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	10/17/2018	Initial release	Verified:				
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description:	Size:	Part number:	
					A	31-00057	
				Coiled cable, 1115 mm, 5C blunt cut to same, 20 AWG, 6.2 mm, TPU, shielded, 30-00921 wire	Scale: 1:1		Sheet 1 of 1