

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210230238](#)
Status: **Active**
Overview: [mPm® DIN Valve Connectors](#)
Description: mPm® DIN Valve Connector, Gray, Form A, PG9 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Black Nitrile Gasket and Screw, Bulk Pack Mounted

Documents:

[Drawing \(PDF\)](#)
[Product Specification STR-1552-001 \(PDF\)](#)
[Packaging Specification PK-121023-C18-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Field Attachable / Accessories
Series [121023](#)
Form A
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm® DIN Valve Connectors](#)
Product Name mPm®
Type Field Attachable Connector
UPC 883906248925

Physical

Cable Diameter N/A
Coupling Type Internal Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 24.040/g
Orientation 90° Angle
Pitch - Mating Interface 18.00mm
Poles 2
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number C18209N21

Reference - Drawing Numbers

Packaging Specification PK-121023-C18-001
Product Specification STR-1552-001
Sales Drawing SD-121023-001

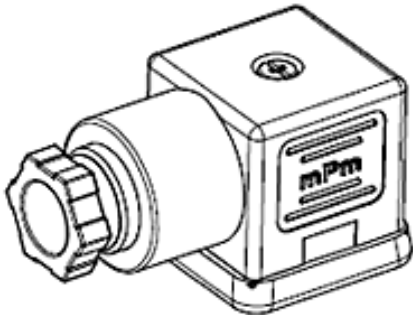

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[121023](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION