



AMMA000606303R3MV1

Search by :

Part Number

Characteristics

Cross reference



NEW



Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

Series Pdf



Product detail		
L(mm) ±		6.47±0.25
W(mm) ±		6.86±0.38
T(mm) ±		3.0Max.
Inductance(uH)		3.3
Tolerance(±%)		20
Test Frequency		100kHz,0.25V
RDC(Ω)Max		0.03
RDC(Ω)Typ		0.028
Isat(A)Typ		13.5
Irms(A)Typ		6
Operating Temperature		−55℃~125℃


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

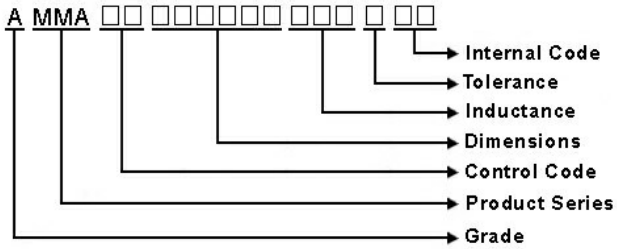

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Filter/Antennas
- RF-Wireless Power Transfer
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



[Inductor](#)



[Resistor](#)



[Powder](#)

Copyrights © 2018. Chilisin. All rights reserved.