



## Mini Wireless Keyboard and Touchpad Mouse - Rechargeable

SKU 402990002

IN STOCK

3 Available

1

ADD TO CART

- Description
- Best-sellers
- Technical Details
- Questions and Answers
- View History

### Description

This product does not include laser pointer.

The iPazzPort Mini Wireless Keyboard specialize designed for Google TV (named as iPazzPort Google TV Mini Wireless Keyboard) which with full set of keys (standard keyboard layout) at such miniature size. It can easily manage those inputs required by internet TV watching as well as web surfing through the Google TV set top box. Beside that, it also a Multi-Touch Pad for Windows, Linux, Mac, game stations, etc.

The iPazzPort Google TV Mini Wireless Keyboard can act as the standard USB keyboard wireless extension. Like normal standard USB keyboard, the iPazzPort Google TV Mini Wireless Keyboard support European characters input (definitely not only European character sets, it can accept any input character sets like Simplify Chinese etc.).

#### Feature:

- 82 keys handheld style keyboard with Touchpad
- Real notebook Touchpad (90 degree touchpad flip, Ultra sensitive, multi-touch and scrolling bar)
- Multi-language supporting
- Multi-touch and Scrolling bar
- Special keys for supporting Google TV set top box
- Unique Page up and Page down key for presentation
- Backlighting: Makes text entry effortless even in low light.
- Plug and play: no need to install software.
- Freedom pairing
- Windows Multimedia Control
- 2.4G : Enjoy long-range wireless control from up to 10 metre (33 feet) away
- 4 in 1: Keyboard, mouse, touchpad and laser pointer 4 in 1.
- Real QWERTY full function mini keyboard with more defined buttons.
- Full Function keys (F1 to F12) and Multi-Media Key (Play, Pause, Next, Previous, Mute, Volume Up, Volume Down).
- Build-in rechargeable Li-ion batteries: Last longer up to two weeks between charges.
- Short recharge time: Around two hours can fully charge the battery.
- Indication light: Multiple indication lights for signal, data transmission and power.


#### Specification:

- Operating distance: 10 meters
- Model: 2.4G RF
- Battery capacity:400mA
- Transmitting power: Max +4dBm
- Working voltage: 3.3V
- Working current: <150mA
- Charge voltage: 4.2V~5.05V
- Charge current: <350mA
- Sleep current: <1mA
- Dimension: 151 X 59 X 12.5mm
- Weight: 100g
- Color: black


Android PC OS  
Mac OS  
Linux(Debian-3.1,Redhat-9.0 Ubuntu-8.10 Fedora-7.0 tested)  
Windows (all) with USB port

**Package Include:**  
Wireless Keyboard and Touchpad  
USB Dongle  
USB Charging Cable  
User's Manual


Best-sellers




Mini Wireless Keyboard a...



Raspberry Pi 3 Model B



Raspberry Pi 2 Model B w...




Grove - Fingerprint Sensor

Technical Details

Dimensions	220mm x 125mm x 30mm
Weight	G.W 148g
Battery	Exclude

Questions and Answers

Have a question about this? Ask people who own it.

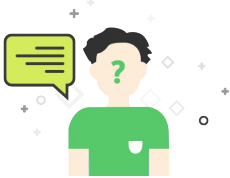

View History



20 pin dual female splitta...



JST 2 Pin power connector



BNC to MCX Converter



RF Explorer EVA carrying c...

POPULAR SEARCHES

- PCB Manufacturing
- PCB Stencil
- Arduino
- XBee
- Arduino Shield
- Beaglebone Black
- Raspberry Pi
- Raspberry Pi Touchscreen
- Linkit
- Cubieboard
- Beaglebone Cape
- FPGA
- Linkit ONE
- Crazyflie 2.0
- Raspberry Pi 3 Model B
- RF Explorer
- DSO Nano v3
- MediaTek X20
- HiKey Board
- rplidar
- raspberry pi relay
- RPLIDAR A2



SHIPPING INFORMATION



KNOWLEDGE BASE



HELP CENTER

Seed Info

Reach Us  
Distributors  
Designers

Downloaded from [Arrow.com](#)

Customer Service

Contact Us  
Customer Support  
Technical Support

Terms and Conditions

Order Information  
Shipping Information  
Payment Information

Stay Tuned

Subscribe to get the latest product releases, activities and tutorials from Seed Studio.

email address



