


Data Sheet | Item Number: 210-133

Busbar; tin-plated; 1000 mm long; Cu 10 mm x 3 mm; white

<https://www.wago.com/210-133>

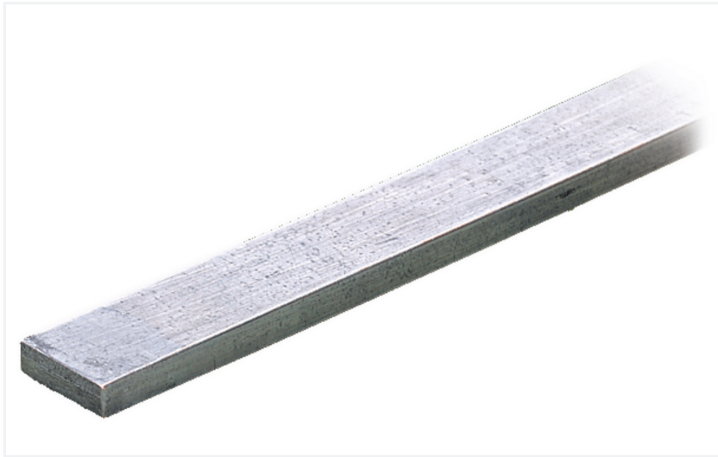

Color: ■ white

Electrical data

Rated current	140 A
---------------	-------

Physical data

Length	1000 mm
--------	---------

Material data

Color	white
Fire load	0 MJ
Weight	266 g

Commercial data

PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454229443
Customs tariff number	7407100000

Product Classification

UNSPSC	39121613
eCl@ss 10.0	27-14-11-39
eCl@ss 9.0	27-14-11-39
ETIM 9.0	EC000485
ETIM 10.0	EC000485
ECCN	NO US CLASSIFICATION

Environmental Product Compliance

RoHS Compliance Status Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 210-133	↓

Documentation

Bid Text			
210-133	19.02.2019	xml 2.54 KB	↓
210-133	23.11.2018	docx 13.39 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 210-133	↓

CAE data	
EPLAN Data Portal 210-133	↓
WSCAD Universe 210-133	↓
ZUKEN Portal 210-133	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Cover

1.1.1.1 Cover



Item No.: 777-303
N-busbar cover; 1000 mm long; transparent

1.1.2 N-busbar

1.1.2.1 Busbar terminal block



Item No.: 210-281
Connector; blue



Item No.: 209-105
Connector; silver-colored

1.1.3 Shield termination

1.1.3.1 Shield clamping saddles



Item No.: 790-108
Shield clamping saddle; 11 mm wide; diameter of compatible conductor; 3 ... 8 mm



Item No.: 790-208
Shield clamping saddle; 12.4 mm wide; 3 ... 8 mm



Item No.: 790-116
Shield clamping saddle; 19 mm wide; diameter of compatible conductor; 7 ... 16 mm



Item No.: 790-216
Shield clamping saddle; 21.8 mm wide; 6 ... 16 mm



Item No.: 790-124
Shield clamping saddle; 27 mm wide; diameter of compatible conductor; 6 ... 24 mm



Item No.: 790-220
Shield clamping saddle; 30 mm wide; 6 ... 20 mm



Item No.: 790-140
Shield clamping saddle; diameter of compatible conductor

1.1.3.2 Shield termination



Item No.: 791-107
Shield clamp; diameter of compatible conductor; 1.5 mm to 6.5 mm; H max. 40 mm; 10 mm wide



Item No.: 791-117
Shield clamp; diameter of compatible conductor; 10 mm to 17 mm; H max. 63 mm; 23 mm wide



Item No.: 791-124
Shield clamp; diameter of compatible conductor; 16 mm to 24 mm; H max. 78 mm; 30 mm wide



Item No.: 791-111
Shield clamp; diameter of compatible conductor; 5 mm to 11 mm; H max. 47 mm; 17 mm wide



Item No.: 790-398
T-connector; for busbars Cu 10 mm x 3 mm; silver-colored

1.1.4 Terminal blocks

1.1.4.1 Common potential terminal block



Item No.: 812-111
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; 16,00 mm²; light gray



Item No.: 812-114
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; blue



Item No.: 812-112
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; dark gray



Item No.: 812-113
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; red



Item No.: 812-104
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; blue



Item No.: 812-101
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; light gray



Item No.: 812-102
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; dark gray



Item No.: 812-103
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; red



Item No.: 812-110
Ground busbar terminal block; for (10 x 3) mm busbars; CAGE CLAMP®; green-yellow



Item No.: 812-100
Ground busbar terminal block; for (10 x 3) mm busbars; Push-in CAGE CLAMP®; 4,00 mm²; green-yellow

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com