

[→ Honeywell.com](#) [→ Automation & Control Solutions](#)[HOME](#)[ABOUT US](#)[KEY INDUSTRIES SERVED](#)[PRODUCTS & INFORMATION](#)[NEWS & EVENTS](#)[SALES & SUPPORT](#)[L](#)

Honeywell Sensing and Control

Search

**1TP8-3**

(Home : Products : Switches » MICRO SWITCH™ Rocker Switches » Power-duty Rocker Switches » TP)

narrow your search

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1701)
- Sensors (6224)
- Switches (9749)
- Wireless (39)

Technology

- Control and Instrumentation (1052)
- Electromechanical (9301)
- Magnetic (541)
- Optical/Infrared (1042)
- Thick Film (1764)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site
WGLA and WPMM
XYR6000™

[find out more](#)

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

Need help?

[Click here to contact us](#)

Actual product appearance may vary.

TP Series Rocker Switch, 1 pole, 2 position, Screw terminal, Flush Panel Mounting

[Sales & Service](#)[Distributor Inventory](#)[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Product Type

MICRO SWITCH™ Rocker

Contact Type

Silver Cadmium Oxide Contacts


Circuitry

SPDT

Action

2 position

Circuitry/Operating action

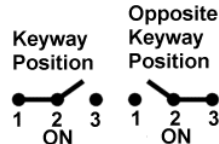

Mounting

Flush Panel

Lamp Type

No button

Termination

Screw

Ampere/Voltage Range (Resistive Load)

0.5 A at 250 Vdc, 0.75 A at 115 Vdc, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac

LED/Lamp/Neon Voltage

L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"

Comment

Silver cadmium oxide contacts

Availability

Global

UNSPSC Code

302119

UNSPSC Commodity

302119 Switches and controls and relays

Series Name

TP

contacts

Customer Service
Technical Support
Global Sales & Service
View Site Demo
Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.

[Meet Dr. Larry](#)

my links

[Login to iCOM](#)
[Login to Rep/AD Portal](#)
[Login to Digital University](#)

News Center

HONEYWELL ANNOUNCES ADDITION TO RELIALIGN™ RESIDENTIAL DOOR INTERLOCK SWITCHES THAT FEATURE RUGGED, PLASTIC HOUSING

HONEYWELL RELEASES UNLIMITED POTENTIAL WITH NEW LIMITLESS™ WIRELESS SWITCHES

HONEYWELL'S XYR6000 WIRELESS POSITION SENSOR ENABLES MONITORING IN HAZARDOUS AREAS AND REMOTE LOCATIONS

MICRO SWITCH
Anniversary site

[Terms & Conditions](#) | [Privacy Statement](#) | [Site Map](#)