


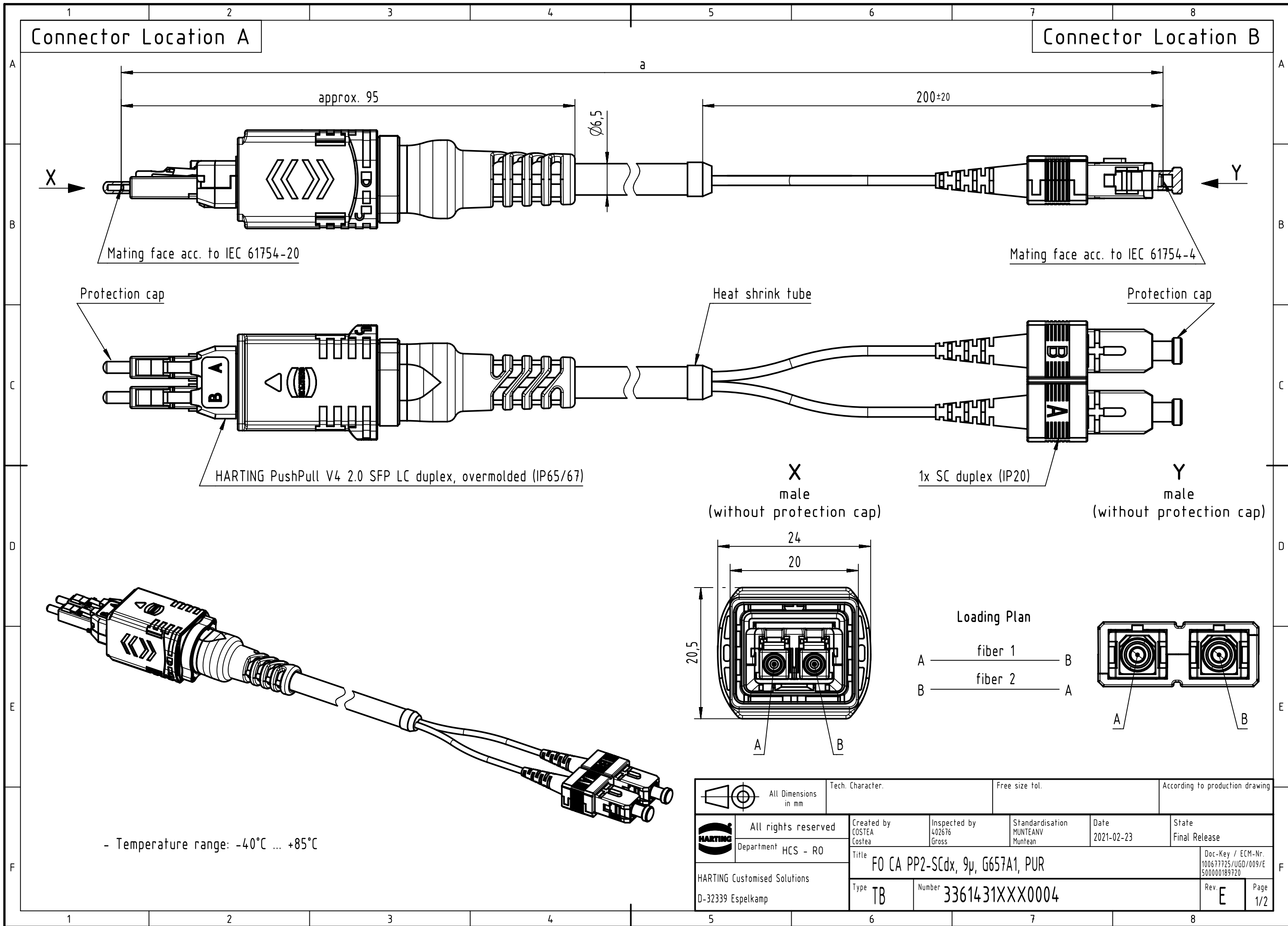

	1	2	3	4	5	6	7	8
A								
B								
C	27	33614311000004	FO Cable, 2-channel, SM, 9/125µm, PUR, black		100			
	26	33614310900004			90			
	25	33614310800004			80			
	24	33614310700004			70			
	23	33614310600004			60			
	22	33614310500004			50			
	21	33614310450004			45			
	20	33614310400004			40			
	19	33614310350004			35			
D	18	33614310300004			30			
	17	33614310250004			25			
	16	33614310200004			20			
	15	33614310150004			15			
	14	33614310140004			14			
	13	33614310130004			13			
	12	33614310120004			12			
E	11	33614310110004			11			
	10	33614310100004			10			
	9	33614310090004			9			
	8	33614310080004			8			
	7	33614310070004			7			
	6	33614310060004			6			
	5	33614310050004			5			
	4	33614310040004			4			
F	3	33614310030004			3			
	2	33614310020004			2			
	1	33614310010004			1			
	Cont. no.	Part no.		Type of cable	Dim. a[m]			
	1	2	3	4	5	6	7	8



All rights reserved
Department HCS - RO



All Dimensions
in mm

Tech. Character.

Free size tol.

According to production drawing

Created by
COSTEA
Costea

Inspected by
402676
Gross

Standardisation
MUNTEANV
Muntean

Date
2021-02-23

State
Final Release

Title
FO CA PP2-SCdx, 9µ, G657A1, PUR

Doc-Key / ECM-Nr.
100677725/UGD/009/E
500000189720

Type
TB

Number
3361431XXX0004

Rev.
E

Page
2/2

HARTING Customised Solutions
D-32339 Espelkamp