

Connectors > Automotive Connectors > Automotive Housings

2366036-2

ACTIVE

Housing for Female Terminals, Wire-to-Wire, 48 Position, .138 in / .118 in [3.5 mm / 3 mm]
Centerline, Gray, Wire & Cable, Power & Signal



TE Internal #: **2366036-2**
TE Internal Description: **48POS,MCON 1.2,RE C HSG ASSY,UNSLD,COD B**

Connector & Housing Type : **Housing for Female Terminals**
Mating Tab Width : **1.15 mm [.045 in]**
Connector System : **Wire-to-Wire**
Number of Positions : **48**
Centerline (Pitch) (mm): **3, 3.5**
Centerline (Pitch) (in): **.118, .138**

Add to List | Similar Products

Digital Datasheet

GET FREE SAMPLES

Compatible Parts & Tooling

SHOP OUR DISTRIBUTORS

North America

See all price breaks

Distributor	1	10,000	Buy
Avnet Electronics 312 in-stock	\$8,570	\$6,150	SHOP NOW
Digi-Key Electronics 201 in-stock	\$8,570	\$5,107	SHOP NOW
Newark element14 312 in-stock	\$4,350	\$4,350	SHOP NOW

We are here to help!

Get in touch with our product experts.



CHAT WITH US



EMAIL US



CALL US

Feedback

Documents

Features

Product Compliance

CAD Files

3D PDF

3D_CVM_CVM_2366036-2_A.pdf

3D

Customer View Model

ENG_CVM_CVM_2366036-2_A.2d_dxf.zip

English

ENG_CVM_CVM_2366036-2_A.3d_igs.zip

English

ENG_CVM_CVM_2366036-2_A.3d_stp.zip

English

Product Specifications

Application Specification

ENG_SS_114-32365_B.pdf

English

Compatible Parts

All Compatible Parts (4)

Filter By Specification

Tooling Parts (1)

Required Parts (2)

Mating parts (1)



MCON Receptacle...
MCON is a series of contact...

From: \$0.058
In-Stock

VIEW PRODUCT



MATING
2366066-2
Housing for Male Terminals...

From: \$2.110
In-Stock

VIEW PRODUCT



TOOLING
4-1579001-1
Hand Crimping Tools...

From: \$708.330
In-Stock

VIEW PRODUCT

Products with Similar Specs

View All Similar Products

THIS PRODUCT

AUTOMOTIVE HOUSINGS

2366036-2

Housing for Female Terminals, Wire-to-Wire, 48 Position, .138 in / .118...



In-Stock


Connector & Housing Type : **Housing for Female Terminals**
Mating Tab Width : **1.15 mm**
Connector System : **Wire-to-Wire**
Number of Positions : **48**
Centerline (Pitch) : **3 mm, 3.5 mm**

TOP RESULTS

AUTOMOTIVE HOUSINGS

2366066-2

Housing for Male Terminals, Wire-to-Wire, 48 Position, .118 in / .138 in...

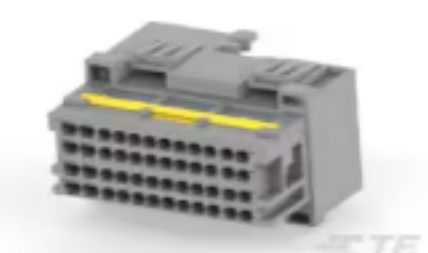

In-Stock

Connector & Housing Type : **Housing for Male Terminals**
Mating Tab Width : **1.15 mm**
Connector System : **Wire-to-Wire**
Number of Positions : **48**
Centerline (Pitch) : **3 mm, 3.5 mm**

AUTOMOTIVE HOUSINGS

2366036-4

Housing for Female Terminals, Wire-to-Wire, 48 Position, .118 in / .138...



In-Stock

Connector & Housing Type : **Housing for Female Terminals**
Mating Tab Width : **1.15 mm**
Connector System : **Wire-to-Wire**
Number of Positions : **48**
Centerline (Pitch) : **3 mm, 3.5 mm**

AUTOMOTIVE HOUSINGS

2366036-3

Housing for Female Terminals, Wire-to-Wire, 48 Position, .138 in / .118...



In-Stock

Connector & Housing Type : **Housing for Female Terminals**
Mating Tab Width : **1.15 mm**
Connector System : **Wire-to-Wire**
Number of Positions : **48**
Centerline (Pitch) : **3 mm, 3.5 mm**

Customers Also Bought



TE Part #: **827230-1**

Housing for Female Terminals, Wire-to-Wire, 12...

View Product



TE Part #: **2282267-1**

Housing for Female Terminals, Wire-to-Wire / ...

View Product



TE Part #: **2-2322948-1**

Housing for Female Terminals, Wire-to-Board, 6...

View Product



TE Part #: **2366066-1**

Housing for Male Terminals, Wire-to-Wire, 48 Position...

View Product

Contact Our Team – 24/7 Support

+1 800 522 6752

Live Chat

See Support Details

Connect With Us



Access Partner Information

Distributors

Suppliers

TE Notice on COVID

Get Answers Now

Authorized Distributors & Resellers

Product FAQs

Samples FAQs

TE Store FAQs

Terms and Conditions of Sale

Samples Terms and Conditions

Select Country

United States (EN)

Germany (DE)

China (中文)

Japan (日本語)

See All Countries