




Quality Products. Service Excellence.


Test & Measurement Rack Cabinet *REFK Series*

1,000 lbs (454 kg) Weight Capacity

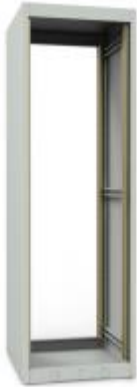

Features

- Available in 20U, 24U, 28U, 32U, 36U, 40U and 44U mounting heights.
- Available in 23" overall width (19" mounting width).
- Available in 17.5", 24.5" and 31.5" overall depths.
- C-channel struts provide cabinet strength, ease and flexibility to adjust mounting rails.
- Solid non-removable side panels.
- Optional flush mounted doors with quarter-turn lock can be mounted to swing either side.
- Knockdown design ships unassembled for easy handling reduced freight cost and shipping protection.
- Simple assembly using one bolt in each corner to lock the sides to the top and bottom.

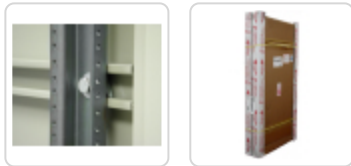

Specifications


- Cabinet frame constructed in 12-gauge steel.
- Drilled and 10-32 tapped flange 19" mounting rails are constructed in 10-gauge steel, include rack unit indicators, and are Zinc-plated to provide superior surface areas for equipment grounding.
- Includes four (4) levelling feet.
- Removable gland plate - over 10" (254 mm) long x 1.5" (38 mm) high opening - with knockouts on the rear bottom of the rack for easy cable access.
- Load rated for up to 1,000 lbs (454 kg).
- Finished in textured RAL9005 black or RAL 7035 light gray powder paint.
- TAA-compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.



You may also consider our new RCK Series cabinet.

Accessories

- | | |
|---|---|
| <ul style="list-style-type: none"> • Universal Rack Shelf • Four Post Mounting Sliding Shelf • Sliding Keyboard Shelf | <ul style="list-style-type: none"> • Adjustable Depth Shelf • Rack Mount Locking Storage Drawer • Four Post Mounting Zero Space Fixed Shelf |
| <ul style="list-style-type: none"> • Four Post Fixed Depth Shelf • PDUs and Outlet Strips • Adjustable Depth Cable Manager • Horizontal Ring Cable Manager • Cable Management Arm • Grounding & Bonding • Light Duty Caster Set • Square Hole Punched Mounting Rail | <ul style="list-style-type: none"> • 10-32 Mounting Hardware • Rack Unit Label • Horizontal Lacing Strip • Horizontal Hinged Cable Manager • Horizontal Steel Finger Cable Manager • Rack Panels • Mounting Rack Rails |

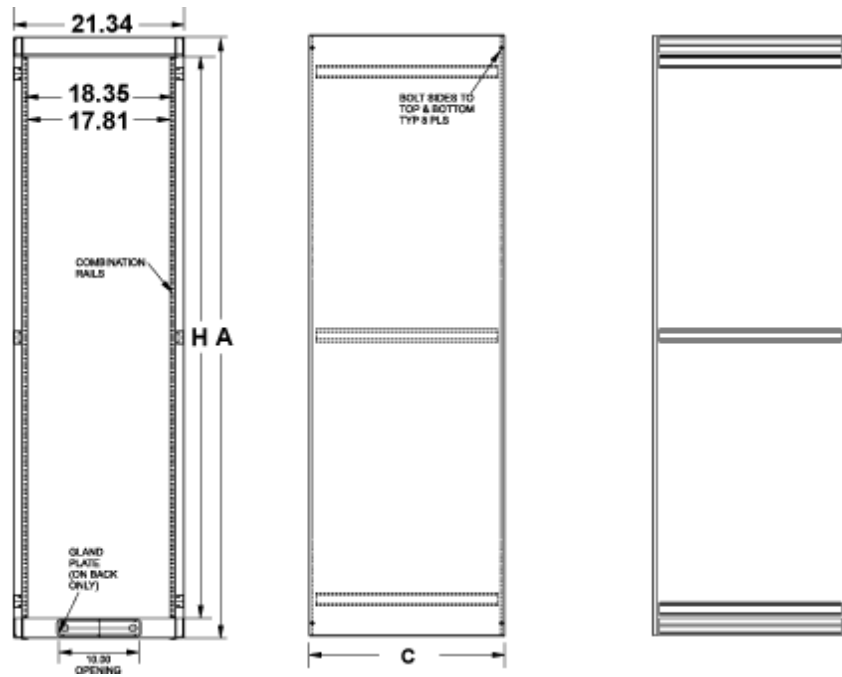

Part No. Black	Part No. RAL 7035 Light Gray	Overall Dimensions			Rack Units	Usable Mounting Dimensions			Alternative Size Part No.
		Height A	Width	Depth C		Height H	Depth	Depth (With Doors)	
REFK1903517BK1	REFK1903517LG1	40.19	21.34	17.50	20U	35.19	16.50	16.00	
REFK1904217BK1	REFK1904217LG1	47.19	21.34	17.50	24U	42.19	16.50	16.00	
REFK1904917BK1	REFK1904917LG1	54.19	21.34	17.50	28U	49.19	16.50	16.00	
REFK1905617BK1	REFK1905617LG1	61.19	21.34	17.50	32U	56.19	16.50	16.00	
REFK1906317BK1	REFK1906317LG1	68.19	21.34	17.50	36U	63.19	16.50	16.00	
REFK1907017BK1	REFK1907017LG1	75.19	21.34	17.50	40U	70.19	16.50	16.00	
REFK1907717BK1	REFK1907717LG1	82.19	21.34	17.50	44U	77.19	16.50	16.00	
REFK1903524BK1	REFK1903524LG1	40.19	21.34	24.50	20U	35.19	23.50	23.00	RCK20U25BK
REFK1904224BK1	REFK1904224LG1	47.19	21.34	24.50	24U	42.19	23.50	23.00	RCK24U25BK
REFK1904924BK1	REFK1904924LG1	54.19	21.34	24.50	28U	49.19	23.50	23.00	RB-AV27
REFK1905624BK1	REFK1905624LG1	61.19	21.34	24.50	32U	56.19	23.50	23.00	
REFK1906324BK1	REFK1906324LG1	68.19	21.34	24.50	36U	63.19	23.50	23.00	RCK36U25BK
REFK1907024BK1	REFK1907024LG1	75.19	21.34	24.50	40U	70.19	23.50	23.00	RCK42U25BK
REFK1907724BK1	REFK1907724LG1	82.19	21.34	24.50	44U	77.19	23.50	23.00	RCK42U25BK
REFK1903531BK1	REFK1903531LG1	40.19	21.34	31.50	20U	35.19	30.50	30.00	RCK20U32BK
REFK1904231BK1	REFK1904231LG1	47.19	21.34	31.50	24U	42.19	30.50	30.00	RCK24U32BK
REFK1904931BK1	REFK1904931LG1	54.19	21.34	31.50	28U	49.19	30.50	30.00	
REFK1905631BK1	REFK1905631LG1	61.19	21.34	31.50	32U	56.19	30.50	30.00	
REFK1906331BK1	REFK1906331LG1	68.19	21.34	31.50	36U	63.19	30.50	30.00	RCK36U32BK
REFK1907031BK1	REFK1907031LG1	75.19	21.34	31.50	40U	70.19	30.50	30.00	RCK42U32BK
REFK1907731BK1	REFK1907731LG1	82.19	21.34	31.50	44U	77.19	30.50	30.00	RCK42U32BK

REFK Locking Doors

Solid Door Part No. Black	Solid Door Part No. RAL 7035 Light Gray	Louvered Door Part No. Black	Louvered Door Part No. RAL 7035 Light Gray	Window Door Part No. Black	Use With REFK Frame		
					Height	Rack Units	Part No.
RSDF19035BK1	RSDF19035LG1	RSDL19035BK1	RSDL19035LG1	REDFP19035BK1	35.00	20U	REFK19035XX
RSDF19042BK1	RSDF19042LG1	RSDL19042BK1	RSDL19042LG1	REDFP19042BK1	42.00	24U	REFK19042XX
RSDF19049BK1	RSDF19049LG1	RSDL19049BK1	RSDL19049LG1	REDFP19049BK1	49.00	28U	REFK19049XX
RSDF19056BK1	RSDF19056LG1	RSDL19056BK1	RSDL19056LG1	REDFP19056BK1	56.00	32U	REFK19056XX
RSDF19063BK1	RSDF19063LG1	RSDL19063BK1	RSDL19063LG1	REDFP19063BK1	63.00	36U	REFK19063XX
RSDF19070BK1	RSDF19070LG1	RSDL19070BK1	RSDL19070LG1	REDFP19070BK1	70.00	40U	REFK19070XX

Solid Door	Solid Door	Louvered Door	Louvered Door	Window Door			
Part No.	Part No.	Part No.	Part No.	Part No.	Use With REFK Frame		
Black	RAL 7035 Light Gray	Black	RAL 7035 Light Gray	Black	Height	Rack Units	Part No.
RSDF19077BK1	RSDF19077LG1	RSDL19077BK1	RSDL19077LG1	REDFP19077BK1	77.00	44U	REFK19077XX

Tags: knock-down, knock down

Data subject to change without notice

© 2022. Hammond Manufacturing Ltd. All rights reserved.