



Fittings for metallic conduits and metallic overbraid

• SCSB-SM Swivel External Thread

Swivel external thread, nickel plated brass.

Features and Benefits

- Two-part fitting of shell and body with external thread
- External thread swivels about main body
- Provides tight, reliable hold of conduit
- Can be secured with locknut




HeliaGuard SCSB-SM Swivel External Thread.

MATERIAL	Nickel Plated Brass (NPB)
Operating Temperature	-100 °C to +300 °C

HF ✓

RoHS ✓

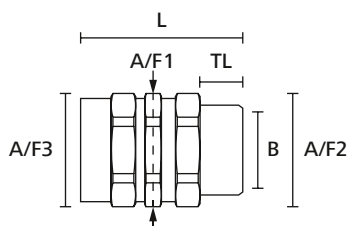

HeliaGuard fitting, straight with swivel external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Thread (A/F2)	A/F Nut (A/F3)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
SCSB12-SM-M16	12	M16	8.5	36.2	17	17	17	9.0	10 pcs.	Metal (ML)	166-34700
SCSB12-SM-PG9	12	PG9	8.5	36.2	17	17	17	8.0	10 pcs.	Metal (ML)	166-34707
SCSB16-SM-M16	16	M16	11.5	38.1	20	20	20	10.0	10 pcs.	Metal (ML)	166-34701
SCSB16-SM-M20	16	M20	11.5	38.1	20	22	20	10.0	10 pcs.	Metal (ML)	166-34702
SCSB16-SM-PG11	16	PG11	11.5	38.1	20	20	20	10.0	10 pcs.	Metal (ML)	166-34708
SCSB20-SM-M20	20	M20	15.3	40.0	26	24	24	10.0	10 pcs.	Metal (ML)	166-34703
SCSB20-SM-PG16	20	PG16	15.3	40.0	26	24	24	10.0	10 pcs.	Metal (ML)	166-34709
SCSB25-SM-M25	25	M25	19.1	47.2	29	29	29	12.0	10 pcs.	Metal (ML)	166-34704
SCSB25-SM-PG21	25	PG21	19.1	47.2	29	29	29	12.0	10 pcs.	Metal (ML)	166-34710
SCSB32-SM-M32	32	M32	26.0	52.6	38	38	38	13.0	2 pcs.	Metal (ML)	166-34705
SCSB32-SM-PG29	32	PG29	26.0	52.6	38	38	38	13.0	2 pcs.	Metal (ML)	166-34711
SCSB40-SM-M40	40	M40	34.6	57.8	48	48	48	14.0	1 pcs.	Metal (ML)	166-34706
SCSB40-SM-PG36	40	PG36	34.6	57.8	48	48	48	14.0	1 pcs.	Metal (ML)	166-34712

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.