

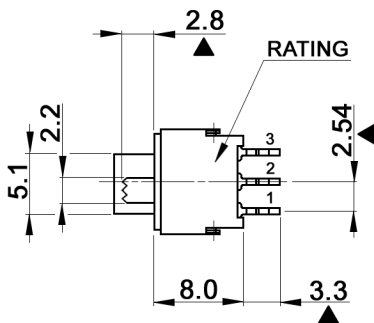
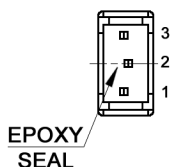


Actuator shown in pos. 1

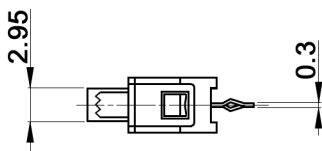

P.C. MOUNTING

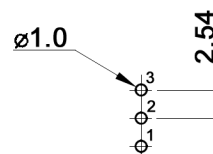

CONTACT ARRANGEMENT

code for x	function	actuator in position 1	actuator opposite to pos. 1
D	On-On	1-2	2-3

code for x	function	actuator in position 1	actuator in center	actuator opposite to pos. 1
E	On-Off-On	1-2	open	2-3

Specifications:

Contact rating:	max. 0.4VA, max. 48V AC or DC, max. 50mA min.: 1µA, 20mV AC or DC
Contact resistance:	50mOhm max.
Insulation resistance:	500MOhm min. at 250V DC
Dielectric strength:	500V, 50Hz for the duration of 1 minute
Operating temperature:	-20°C to +85°C
Electrical life:	min. 40 000 cycles
Soldering conditions:	wave-soldering: 260 +/-5°C, 5 +/-1sec.
Protection:	IP67
Material:	Actuator: PBT, yellow Housing: brass, nickel plated Case: PA 66 (UL94V-0) Contact / terminals: phosphor bronze, gold plated over nickel barrier Cap: silicone rubber

Compliance: RohS III (2015/863/EU)

Tolerances: 0.00: ±0.25mm 0.0: ±0.40mm			Date	Name	ASE 1 x	
			03/14	dr		
					30 30 60	
Material	06/20	dr	knitter-switch			Page
Modifications	Date	Name				1/1