


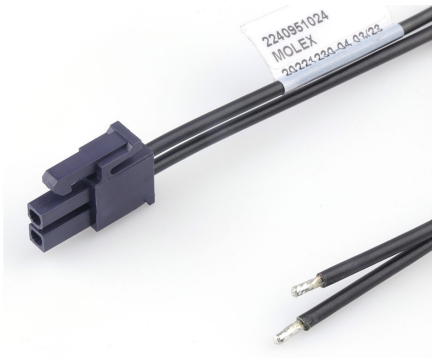

**Part Number :** [2240951023](#)  
**Product Description :** Mini-Fit Versa-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 4.20mm Pitch, Dual Row, 300.00mm Length, 2 Circuits, Black  
**Series Number :** 224095  
**Status :** Active  
**Product Category :** Power and Signal Cable Assemblies



Documents & Resources

**Drawings**  
[2240951023\\_sd.pdf](#)

Product Environment Compliance

Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                    |
| REACH SVHC         | Not Contained per D(2024)7663-DC (21 Jan 2025)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

---

## Part Details

### General

|                        |                                                                                                                          |
|------------------------|--------------------------------------------------------------------------------------------------------------------------|
| Status                 | Active                                                                                                                   |
| Category               | Power and Signal Cable Assemblies                                                                                        |
| Series                 | 224095                                                                                                                   |
| Description            | Mini-Fit Versa-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 4.20mm Pitch, Dual Row, 300.00mm Length, 2 Circuits, Black |
| Application            | Power, Wire-to-Board, Wire-to-Wire                                                                                       |
| Assembly Configuration | Single Ended Connector                                                                                                   |
| Connector to Connector | Mini-Fit Versa-to-Pigtail                                                                                                |
| Product Name           | Mini-Fit Versa Color                                                                                                     |
| Type                   | Discrete Wire Assembly                                                                                                   |
| UPC                    | 196823353635                                                                                                             |

### Electrical

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 9.0A |
| Voltage - Maximum             | 600V |

### Physical

|                                |                |
|--------------------------------|----------------|
| Cable Length                   | 300.00mm       |
| Circuits (Loaded)              | 2              |
| Circuits (maximum)             | 2              |
| Color - Resin                  | Black          |
| Gender                         | Female-Pigtail |
| Lock to Mating Part            | Yes            |
| Material - Metal               | Brass          |
| Material - Plating Mating      | Tin            |
| Material - Plating Termination | Tin            |
| Material - Resin               | Nylon          |
| Net Weight                     | 13.901/g       |
| Number of Rows                 | 2              |
| Overmolded                     | No             |
| Packaging Type                 | Bag            |

|                             |                      |
|-----------------------------|----------------------|
| Pitch - Mating Interface    | 4.20mm               |
| Single Ended                | Yes                  |
| Termination Interface Style | Crimp or Compression |
| Wire/Cable Type             | UL 1015              |
| Wire Size (AWG)             | 16                   |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                     | Part Number  |
|-----------------------------------------------------------------|--------------|
| Mini-Fit Jr. Dual Row Plug Housings                             | <u>46993</u> |
| Mini-Fit Jr. Right-Angle Dual Row Reflow Solder Capable Headers | <u>46991</u> |

---

This document was generated on Apr 26, 2025