

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0740951064

Status:

Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Header, Single Row, Vertical, Shrouded, 4 Circuits, 0.76µm Gold (Au)
Selective Plating over Tin (Sn) Plating

Documents:

3D Model	Product Specification PS-74095-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70873-0014-001 (PDF)
3D Model (PDF)	Test Summary TS-70541-100-001 (PDF)
Product Specification PS-70400-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification


CSA	LR19980
UL	E29179

General

Product Family	PCB Headers
Series	74095
Application	Signal, Wire-to-Board
Overview	SL Modular Connectors
Product Name	SL
UPC	884982385061

Physical

Breakaway	No
Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Durability (mating cycles max)	50
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	0.829/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	4.41mm
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Tube
Pitch - Mating Interface	2.54mm
Plating min - Mating	0.762µm
Polarized to Mating Part	Yes
Polarized to PCB	No
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole - Compliant Pin

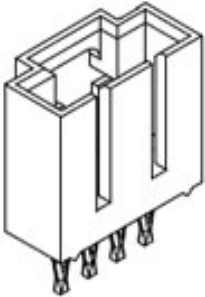

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[74095](#) Series

Mates With

SL Crimp Housing [70066](#) Option N, [70066](#)
Option G, [70430](#) Option G, [70400](#) Option G

Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	250V

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-70873-0014-001
Product Specification	PS-70400-001, PS-74095-001-001
Sales Drawing	SD-74095-001
Test Summary	TS-70541-100-001

This document was generated on 03/30/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION