





DB UNLIMITED

Part Number:	1	
	DRAWN	5/20/2019
	CJ	
Description:	CHECKED	5/21/2019
	C.H.	
	APPROVED	5/21/2019
	C.E.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

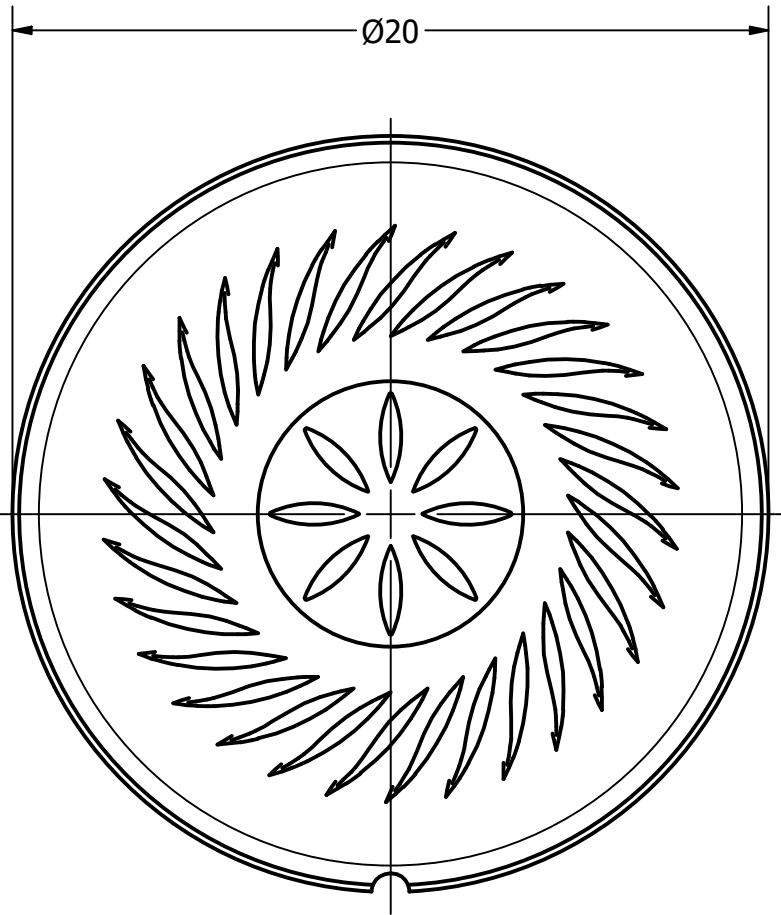

Side View

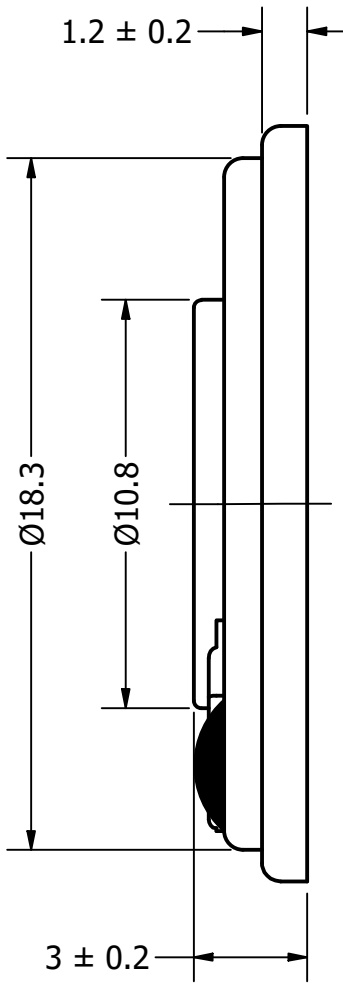

Bottom View

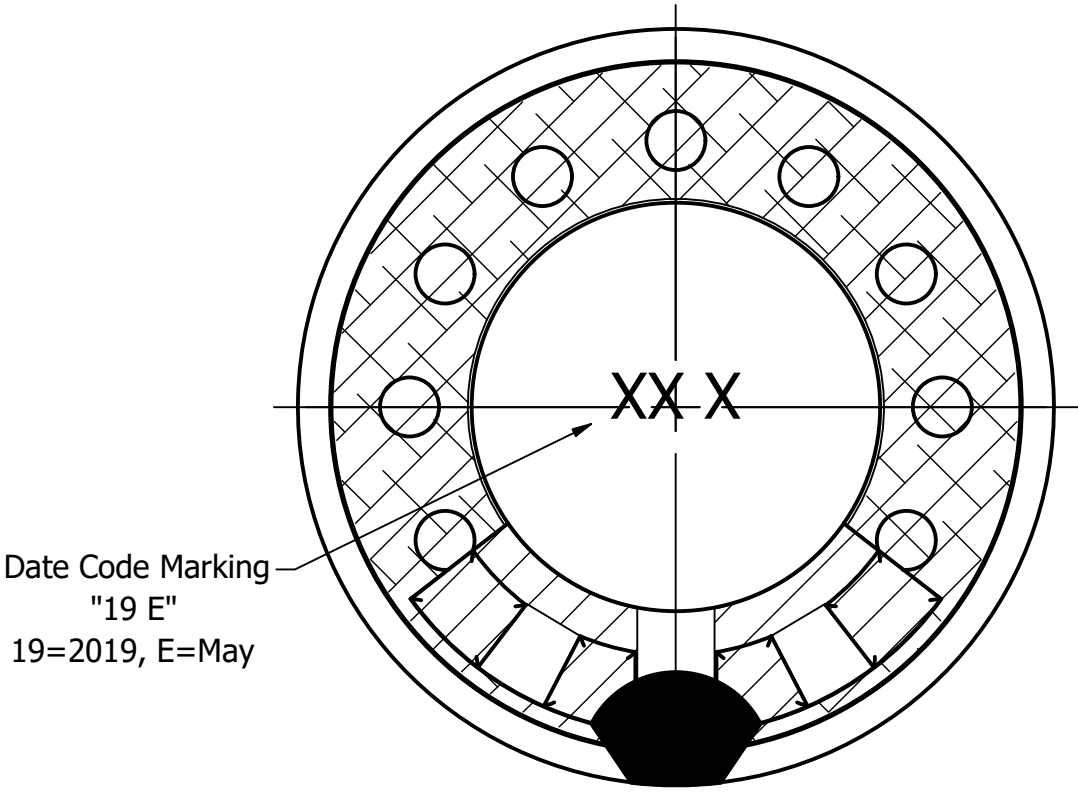

Items	Specifications	Conditions	REVISION HISTORY			
Sound Pressure Level	95	dB (@ 10cm)	REV	DESCRIPTION	DATE	APPROVED
Resonant Frequency	800	Hz	1	Released from Engineering	2/5/2014	J.S.
Frequency Range	800 ~ 20,000	Hz		Updated to new drawing template, power, frequency, temps	5/21/2019	C.E.
Nominal Power	0.3	W				
Max. Power	0.5	W				
Impedance	8	Ω				
Cone Material	Mylar		NOTES			
Mount Type	Flush Mount		1) All dimensions are in mm unless otherwise noted			
Storage Temperature	-30 ~ +60	°C	2) All tolerances are ± 0.5 mm unless otherwise noted			
Operating Temperature	-20 ~ +60	°C	3) All parts meet RoHS			
Weight	2.4	g	4) Subject to change or redrawn without notice			