

[→ Honeywell.com](#) [→ Automation & Control Solutions](#)[HOME](#)[ABOUT US](#)[KEY INDUSTRIES SERVED](#)[PRODUCTS & INFORMATION](#)[NEWS & EVENTS](#)[SALES & SUPPORT](#)[LOGIN](#)

Honeywell Sensing and Control

Search



12TW1-10A

(Home : Products : TW » Switches » MICRO SWITCH™ Toggle Switches)

narrow your search

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1701)
- Sensors (6224)
- Switches (9749)
- Wireless (21)

Technology

- Electromechanical (9301)
- Flexible Heaters (140)
- Microstructure (1486)
- Optical/Infrared (1042)
- Thick Film (1764)
- More...



Actual product appearance may vary.

TW Series Toggle Switch, 2 pole, 3 position, Solder terminal, Locking Lever, Military Part Number MS27754-38A

[Sales & Service](#)[Distributor Inventory](#)

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site
WGLA and WPMW
XYR6000™

[find out more](#)

white papers


Wireless Switches Offer Unlimited Benefit
Basic Switches Are Not Created Equal
Applying Precision Switches
Sensors for Medical Devices
New Ways to Measure Torque
Choosing Safety Switches
Specifying Hour Meters

Need help?

[Click here to contact us](#)[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Circuitry/Operating action

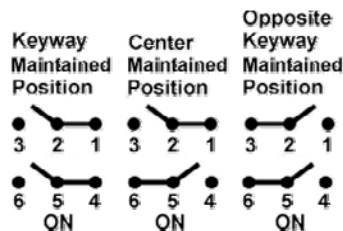

MICRO SWITCH™ Toggle Switch



Locked in
three position

Product Type

Lever Lock

Ampere/Voltage Range (Resistive Load)

0.1 A to 5.0 A at 0.5 Vac to 115 Vac, 0.1 A to 5.0 A at 0.5 Vdc to 28 Vdc

Circuitry

DPDT

Action

3 position

Mounting

Bushing 15/32 in

Termination

Solder

MIL Spec. Number

MS27754-38A

Lever Type

Locking

UL/CSA

L117: 5 A at 125 Vac

Comment

Fine silver contacts

Availability

Global

UNSPSC Code

30211908

UNSPSC Commodity

30211908 Toggle switches

Series Name

TW

[Terms & Conditions](#) | [Privacy Statement](#) | [Site Map](#)