

[Products](#)[Customize Your Parts](#)[Industries Solutions](#)[Search](#)[News & Events](#)[First Time?](#)[Home](#) / [Products](#) / [M Series](#) / [Guided M8](#)

Product Line

[Single Pair Ethernet](#) >[ZConnect](#) >[Ceres](#) >[X-Lok](#) >[M Series](#) >[Accessory](#)[M5](#)[Guided M8](#)[M8](#)[M10.5](#)[M12 \(A\)](#)[M12 \(B\)](#)[M12 \(D\)](#)[M12 \(I\)](#)[M12 \(K\)](#)[M12 \(L\)](#)[M12 \(S\)](#)[M12 \(T\)](#)[M12 \(V\)](#)[M23](#)[FLOS & FLOS+](#) >[Power](#) >[RBL](#) >[HS-Lok](#) >[NMEA 2000](#) >[Heavy Duty Shielded](#) >[RJ](#) >[USB](#) >[SSL](#) >[HDMI](#) >[DVI](#) >[Fiber Optic](#) >[RF](#) >[Cable Joiner](#) >[Cable Gland](#) >[Pressure Relief Vent](#) >[LED Light Guide](#) >[D-Sub](#) >

8A-05AMMM-SL7A01

Operating Temperature: -20°C ~ +80°C

Transmission Speed: N/A

Shielded: Metal, Non-shielded

Jacket Material: PVC

Certificate: UL2238

You must login first for view the price


Quantity

- 1 +

Check Stock

Add to Cart

Inquiry

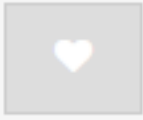

Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

▼

Search

Add to Cart

Inquiry

Specifications	Download / CAD
Nominal Current 1.5A	Connector Type Overmolded
Shielded Metal, Non-shielded	No. of Contacts 05
Connector Gender Male	Backshell Straight
Mating Style Screw Thread	IP Rating IPX7
Assembly Style N/A	
<div> More Options</div>	

People Also Bought

