



**order part 06015KA-24N-AT-00 Ball Bearing
Fan DC Axial Fans**

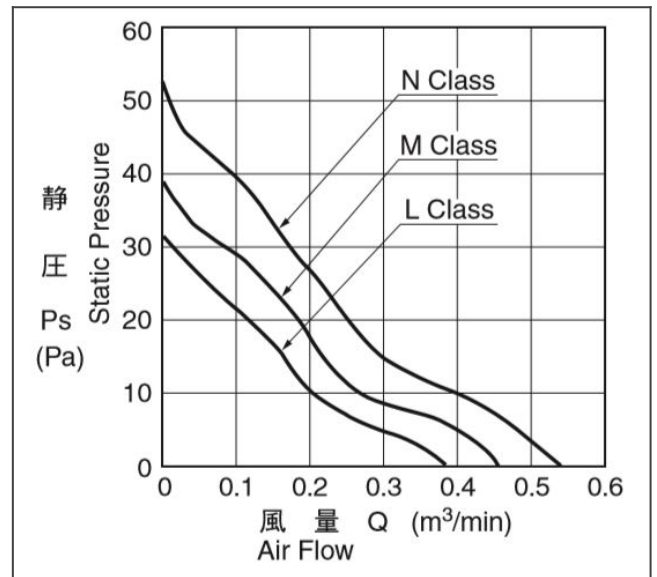


06015KA characteristic chart



06015KA panel cut out

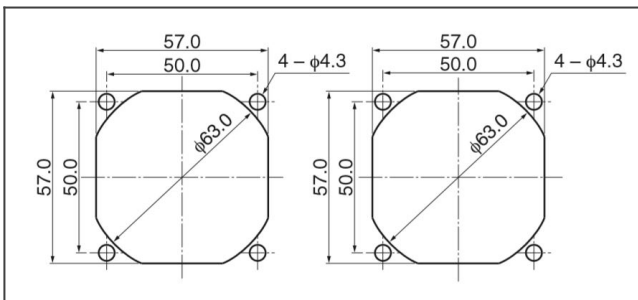

06015KA product drawing

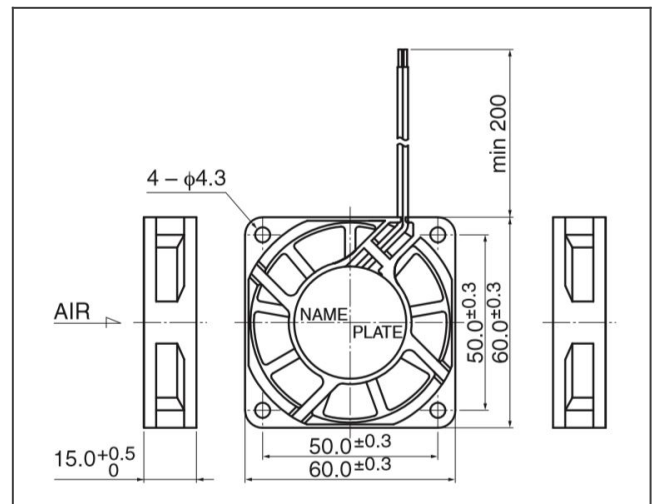

Detailed Specifications

Fan Size:	60[mm]
Fan Width:	15[mm]
Max. Air Flow:	18.4[CFM]
Max. Air Flow:	0.52[m3/min]
Max. Static Pressure:	0.21[In H2O]
Fan Speed:	4600[RPM]
Noise:	34[dB]
Life Expectancy:	25 degree C 70,000 Hours[L10]
Bearing Type:	Ball Bearing
Speed Control:	-
Nominal Voltage:	24[V]
Operating Voltage Lower:	10[V]
Operating Voltage Upper:	27.6[V]
Current:	0.1[A]
Input Power:	2.4[W]
Mass:	45[g]
IP Rating:	Standard

DC Axial Fans