

## Control cabinet feed-through - VS-BH-M12FS-8CON-RJ45/180 - 1405060


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Control cabinet feed-through, M12, 8-pos., A-coded on RJ45 socket, socket input 180°, IP65/67



### Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 298551
GTIN	4046356298551
Weight per Piece (excluding packing)	36.500 g
Custom tariff number	85366990
Country of origin	Germany

### Technical data

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP65
	IP67

#### General

Rated current at 40°C	1 A
Rated voltage	50 V
Number of positions	8
Signal type/category	Ethernet CAT5 (IEC 11801:2002)
Insertion/withdrawal cycles	≥ 100

#### Material

# Control cabinet feed-through - VS-BH-M12FS-8CON-RJ45/180 - 1405060

## Technical data

### Material

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Material of grip body	PA

### Standards and Regulations

Flammability rating according to UL 94	V0
--	----

### Environmental Product Compliance


China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Exposition  
drawing


Exploited  
drawing

Dimensional drawing

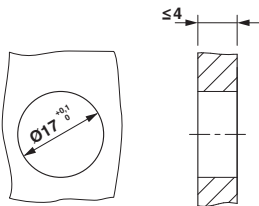

Panel cutout

Dimensional drawing

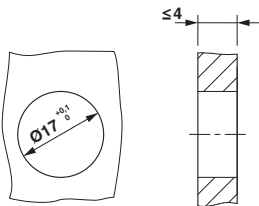

Panel cutout

## Approvals

### Approvals

Approvals

EAC

Ex Approvals

## Control cabinet feed-through - VS-BH-M12FS-8CON-RJ45/180 - 1405060

### Approvals

---

#### Approval details

EAC B.01742
-------------

---

Phoenix Contact 2016 © - all rights reserved  
<http://www.phoenixcontact.com>