

Pressure screw - HC-DS-PG21-T - 1772706

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Pressure screws, with flared cable guard, clamping area 13 mm ... 20 mm, for housing with Pg21 support

RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 037352
GTIN	4017918037352
Weight per Piece (excluding packing)	46.340 g
Custom tariff number	74199990
Country of origin	Germany

Technical data

Dimensions

Clamping range of the strain relief clip	13.00 mm ... 20.00 mm
--	-----------------------

General

Material, pressure screw	Nickel-plated brass
--------------------------	---------------------


Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Pressure screw - HC-DS-PG21-T - 1772706

Drawings

Dimensional drawing

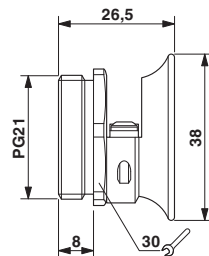

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27144420
eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27149100
eCl@ss 5.1	27149100
eCl@ss 6.0	27149100
eCl@ss 7.0	27069215
eCl@ss 9.0	27144420

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 6.0	EC000814
ETIM 7.0	EC000814

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	31161514
UNSPSC 18.0	31161514
UNSPSC 19.0	31161514
UNSPSC 20.0	31161514



Pressure screw - HC-DS-PG21-T - 1772706

Classifications

UNSPSC

UNSPSC 21.0	31161514
-------------	----------

Phoenix Contact 2021 © - all rights reserved
<http://www.phoenixcontact.com>