


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

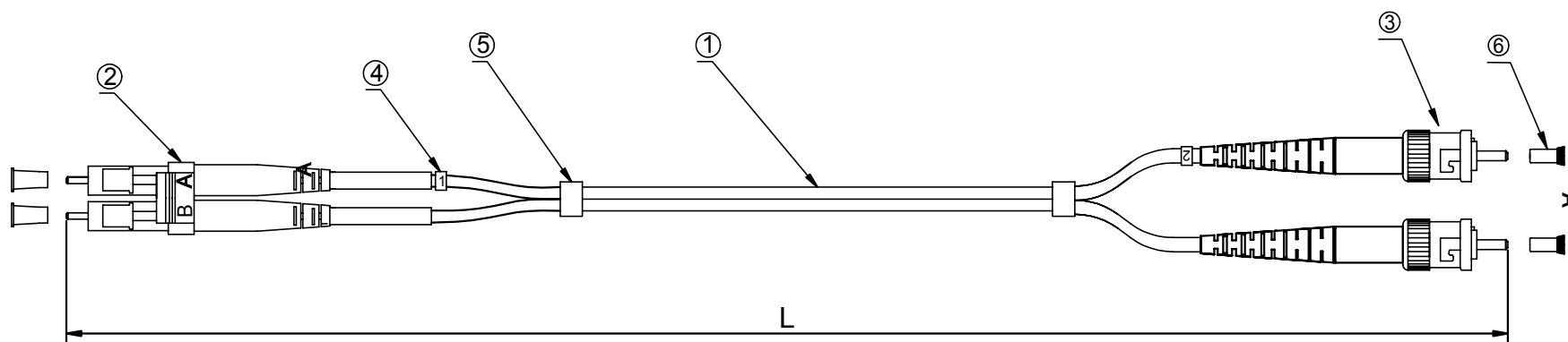

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
913M-2-1-00100-PL	671-448-A	1000±100	Orange
913M-2-1-00200-PL	671-448-B	2000±100	Orange
913M-2-1-00300-PL	671-448-C	3000±100	Orange
913M-2-1-00500-PL	671-448-D	5000±100	Orange
913M-2-1-00700-PL	671-448-E	7000±100	Orange
913M-2-1-01000-PL	671-448-F	10000±100	Orange
913M-2-1-01500-PL	671-448-G	15000±100	Orange
913M-2-1-02000-PL	671-448-H	20000±100	Orange
913M-2-1-02500-PL	671-448-I	25000±100	Orange

NOTES:

Insertion loss < 0.3 dB

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	ST MM Connector (Metal housing Red/black boot)
2	LC MM Duplex Connector (Beige housing White boot)
1	2.0mm,Duplex,MM-62.5/125 OM1, OFNP, Optical Fiber Cable(Orange)
No.	Description

CnC Tech, LLC
Industrial Cable and Connector Technology

		TITLE		Patch Cord, LC-ST,MM-62.5/125 OM1, Duplex, OFNP, orange, 2.0mm, xxM	
UNIT		P/N		DRAWN BY	
unless otherwise stated Tolerances mm XXX.XX ±0.3 XX.XX ±0.2 X.XX ±0.1		Customer P/N		CHECK BY	
SIZE A4		SCALE Free		PAGE 1/1	
				APPROVAL BY	