




TOP VIEW

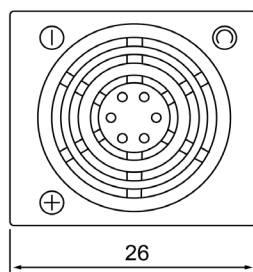

SIDE VIEW

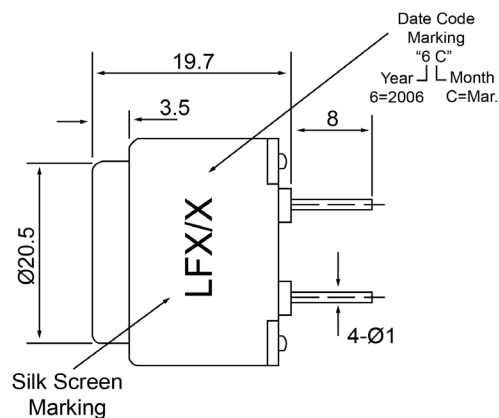

BOTTOM VIEW

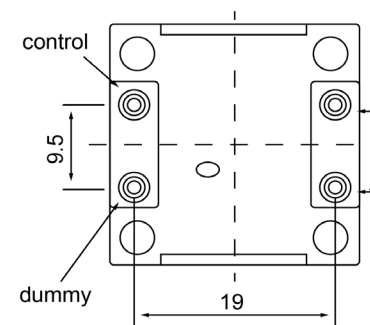

Specifications

Description	Value	Unit
Technology	Electro-Mechanical	
Resonant Frequency	400	(Hz)
Rated Voltage	24	(V)
SPL @ 10cm	95	(dBA)
Tone	Single Tone	
Mount Type	Thru Hole	
Voltage Range	20 ~ 28	(V)
Max Rated Current	50	(mA)
Housing Material	ABS	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-30 ~ +70	°C
Weight	17	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

Electro-Mechanical Indicator

IE260424-1