




+ CONNECTORS
RF CONNECTORS

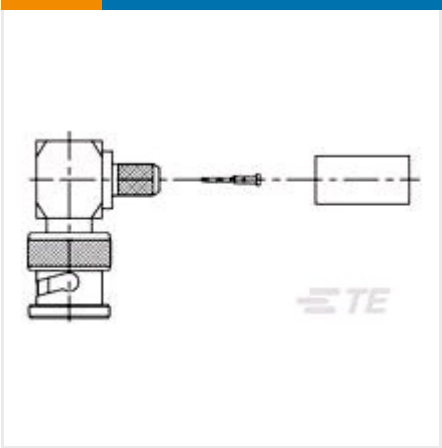

✓ Active

TE CONNECTIVITY (TE)
BNC R/A Plg Hex 75Ohm Silver Pltd RG179B
[Miniature Coax](#) | [HMX](#)

1-1337440-0
TE Internal Number: 1-1337440-0

[EU RoHS Compliant with Exemptions](#)
[EU ELV Compliant with Exemptions](#)

Connector Interface BNC

Connector Style Plug

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Impedance (Ω) 75

Cable Type Raychem 7530A1314, Raychem 7530H1444, Raychem CLFH-179, Raychem EPD 46504R, RG 179B, RG 187A, URM 111

↓ **PRODUCT DRAWING**
[English](#)

DOCUMENTATION

Product Drawings

BNC ELBOW PLUG CRIMP 75 OHM RG179B/U, 187A/U, URM111
PDF
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Interface BNC Connector Style Plug Sealable No Connector & Contact Terminates To Wire & Cable
Configuration Features Number of Positions 1
Electrical Characteristics Impedance (Ω) 75
Body Features Cable Connector Orientation Right Angle Body Material Brass Body Plating Material Silver Body Insulation With
Contact Features Crimp Type Hex Center Contact Plating Material Silver Center Contact Material Brass
Termination Features Termination Method to Wire & Cable Crimp
Dimensions Mated Outer Diameter (Approximate) 14.529 mm [.572 in]
Usage Conditions Cable Type Raychem 7530A1314, Raychem 7530H1444, Raychem CLFH-179, Raychem EPD 46504R, RG 179B, RG 187A, URM 111
Operation/Application Operating Frequency (GHz) 2
Packaging Features Packaging Method Box Packaging Quantity 50
Other Dielectric Material PTFE Gasket Material Silicone Rubber Coupling Nut Material Brass Grade Professional

Statement of Compliance

Statement of Compliance

PDF
