



Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshow
- Support


United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > Electrical Commercial & Industrial Products Catalog > Terminals, Kits and Tools > Terminals > 3M™ Scotchlok™ Female Disconnects > 3M™ Scotchlok™ Female Disconnect, Nylon Insulated w/Insulation Grip Bullet Style, MNG18-156DFIK-A

Find An Account Rep Where To Buy (Find A Distributor) Contact Us

3M™ Scotchlok™ Female Disconnect, Nylon Insulated w/Insulation Grip Bullet Style, MNG18-156DFIK-A

3M ID 80611444235 UPC# 00051138980788 3M Product Number MNG18-156DFIK-A

Print Share

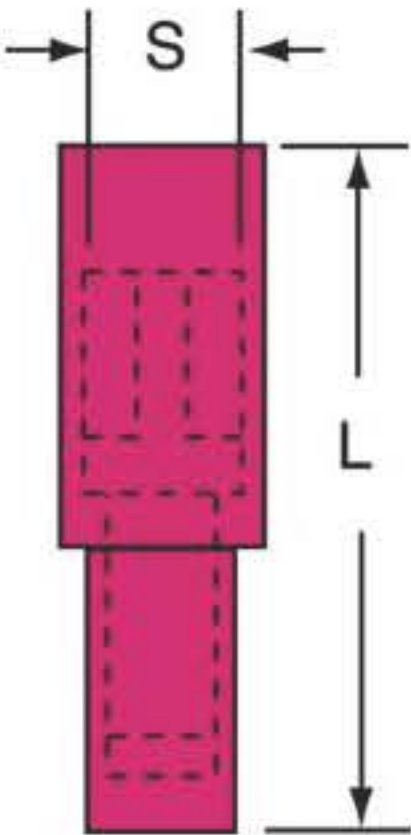

Network Access Message: The page

3M™ Scotchlok™ Female Disconnect - Nylon Insulated with Insulation Grip Bullet Style, MNG18-156DFIK-A, 22-18 AWG

Need Help?

Questions? We can help
Contact Us

- Overview
- Documentation

Specifications

Barrel Inside Diameter	0.145 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
Conductor Sizes	22 - 18 AWG
Fastener Orientation	Female
Insulation Material	Nylon with Insulation Grip
Length (L)	0.99 Inch
Maximum Insulation Outer Diameter	0.15 Inch
Packaging	1000 per bulk box
Pad Width	0.156 Inch
Terminal Style	Bullet Snap Plug
Terminal Type	Disconnect