


OA180AP Series



AC Fans - 115, 230V
176mm x 89mm (6.9" x 3.5")

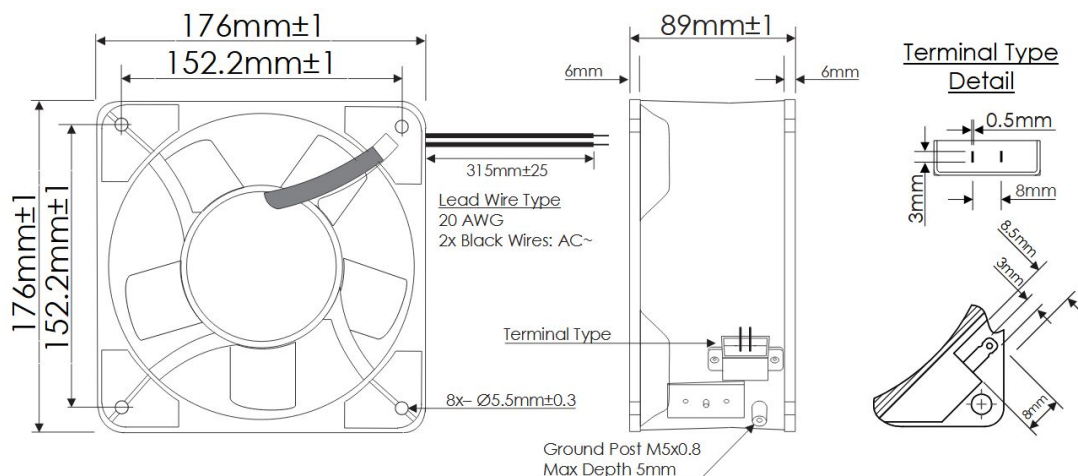

Frame	Die Cast Aluminum, Black Finish	Operating Temperature -20°C ~ +70°C Storage Temperature -40°C ~ +100°C Life Expectancy 60,000 Hours (L10 at 40°C) Weight: 4.0 lbs.	Static Pressure ("H₂O") Airflow (CFM) PQ Airflow Data specifications are for 60 Hz operation
Impeller	PBT, UL94 V-0 Plastic		
Connection	2x Lead Wires, UL 1015 20 AWG, or Terminals		
Motor	Capacitor Induction, Thermally Protected		
Bearing System	Ball Bearings		
Dielectric Strength	1500 VAC/min, <1mA		
Insulation Resistance	≥10M Ohm @ 500 VAC		

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Frequency (Hertz)	Rated Power (Watts)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA180AP-11-1*B	115	100 ~ 120	50 / 60	60 / 70	2700 / 3175	361 / 409	62	0.67 / 0.84
OA180AP-22-1*B	230	200 ~ 240	50 / 60	60 / 70	2700 / 3175	361 / 409	62	0.67 / 0.84

* Insert "T" for Terminal type power connection, or "W" for Wire Lead type power connection.