




2-215307-0 Product Details

Share Print Email

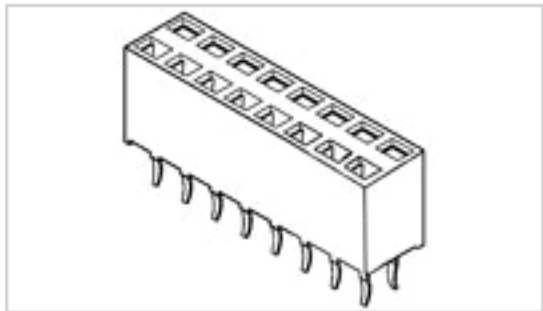

Active

View 3D PDF

.100 inch AMPMODU Receptacles

2X20P HV100 REC CON. TE, 7.0MM

2-215307-0

TE Internal Number: 2-215307-0

Product Highlights View All

- Connector
- HV-100
- 20 Positions
- Number of Rows = Dual
- Standard Profile

Pricing & Availability

Request Sample

Add to My Part List

Buy Product through
Distributor

Feedback

Documents Features Compliance

Please Note:
Use the Product Drawing for all design activity

Product Type Features

Product Type	Connector
Connector Series	HV-100
Profile	Standard
Sealed	No
PCB Mounting Orientation	Vertical
PCB Mount Retention	With
PCB Mount Retention Type	Retention Solder Tails
Closed Entry	With
Board Standoff	With

Mechanical Attachment

Holddown Feature	Without
------------------	---------

Termination Features

Termination Method to PC Board	Through Hole - Solder
Termination Post Length (mm [in])	3.10 [0.122]

Dimensions

Connector Height (mm [in])	7.00 [0.276]
----------------------------	--------------

Body Features

Closed Bottom	With
---------------	------

Contact Features

Contact Plating, Mating Area, Material	Gold (30)
Contact Base Material	Phosphor Bronze
Solder Tail Contact Plating	Tin

Housing Features

Centerline, Matrix (mm [in])	2.54 [.100]
Housing Entry Style	Top
Housing Material	Polyester - GF
Housing Color	Green

Configuration Features

Number of Positions	20
Number of Rows	Dual
Mounting Pattern (mm [in])	2.54 [.100]
Stackable	Yes

Industry Standards

Government/Industry Qualification	No
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
RoHS/ELV Compliance History	Always was RoHS compliant
UL Flammability Rating	UL 94V-0

Other

Brand	AMP
-------	-----

Related Products

Not quite the product
you're looking for?

Find Similar Products

View Part in Product
Feature Selector

Check for Tooling

Corporate Information

About TE
Investors
News Room
Supplier Portal
Careers
Terms & Conditions
Privacy Policy
Global Accessibility Statement

Quick Links

Distributor Inventory
Product Cross Reference
Documents & Drawings
Product Compliance Support Center
Site Map

Customer Support

Email or Chat With Us
Find a Phone Number
Knowledge Base
Manage Your Account

Keep Me Informed

