

PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
5-1437710-5	2 WAY MALE CONNECTOR	YES	4.66 gr.	I	I	I	BLACK	LIGHT BLUE	REDDISH BROWN	HS - PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
5-1437710-6	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
5-1437710-7	2 WAY MALE CONNECTOR	NO	4.64 gr.	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
5-1437710-8	2 WAY MALE CONNECTOR WITH RETAINER		4.84 gr.	I	I										


PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
6-1437710-6	2 WAY MALE CONNECTOR	YES	4.66 gr.	I	I	I	NATURAL	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
6-1437710-7	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
6-1437710-8	2 WAY MALE CONNECTOR	NO	4.64 gr.	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
6-1437710-9	2 WAY MALE CONNECTOR WITH RETAINER		4.84 gr.	I	I										

PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
-	2 WAY MALE CONNECTOR	YES	-	I	I	I	RED	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
7-1437710-0	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
-	2 WAY MALE CONNECTOR	NO	-	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
7-1437710-1	2 WAY MALE CONNECTOR WITH RETAINER		4.84 gr.	I	I										

PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
5-1437710-9	2 WAY MALE CONNECTOR	YES	4.66 gr.	I	I	I	BLUE	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
6-1437710-0	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
6-1437710-1	2 WAY MALE CONNECTOR	NO	4.64 gr.	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
6-1437710-2	2 WAY MALE CONNECTOR WITH RETAINER		4.84 gr.	I	I										

PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
6-1437710-3	2 WAY MALE CONNECTOR	YES	4.66 gr.	I	I	I	GRAY	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
6-1437710-4	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
6-1437710-5	2 WAY MALE CONNECTOR	NO	4.64 gr.	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
-	2 WAY MALE CONNECTOR WITH RETAINER		-	I	I										


PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS			SUITABLE FOR		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HUOSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
7-1437710-2	2 WAY MALE CONNECTOR	YES	4.66 gr.	I	I	I	YELLOW	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER	0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED	1-1437713-1 10.22-0.351 BLACK 1-1437713-2 10.50-1.001 RED 1-1437713-3 11.501 BLUE	I-1437713-4
7-1437710-3	2 WAY MALE CONNECTOR WITH RETAINER		5.06 gr.	I	I	I									
7-1437710-4	2 WAY MALE CONNECTOR	NO	4.64 gr.	I	I		RED						0-1437709-9 10.22-0.35mm ² GOLD PLATED 1-1437709-0 10.50-1.00mm ² GOLD PLATED 1-1437709-7 11.50mm ² GOLD PLATED 1-1437709-4 10.22-0.35mm ² TIN PLATED 1-1437709-5 10.50-1.00mm ² TIN PLATED 1-1437709-6 11.50mm ² TIN PLATED		
7-1437710-5	2 WAY MALE CONNECTOR WITH RETAINER		4.84 gr.	I	I										

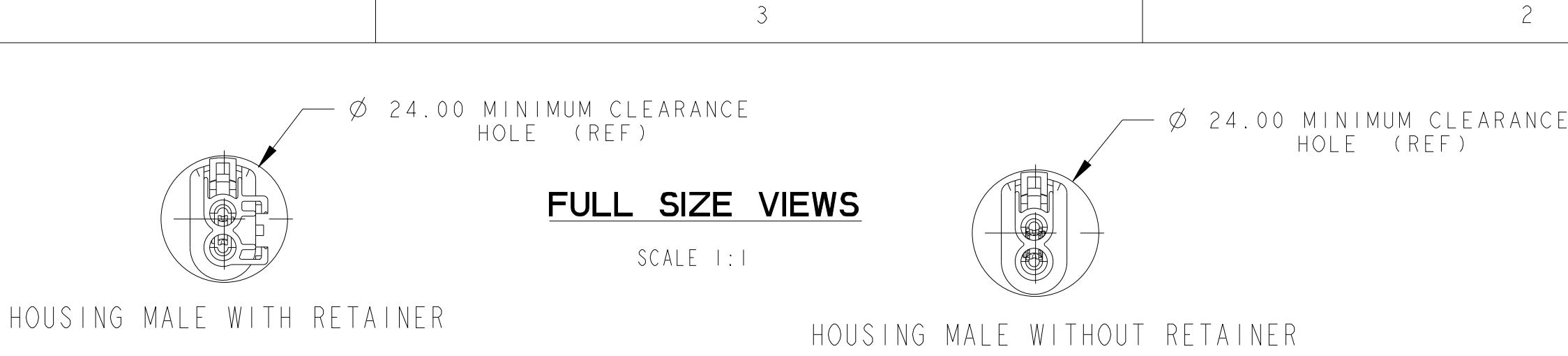


REVISIONS				
P	LTN	DESCRIPTION	DATE	OWN
A3		REDRAWN FOR ECR-08-013212	03.JAN2008	DS
A4		ECR-15-008793	16.JAN2015	GN
A5		PART REV CORRECTION 5-1437710-5-6-7-8	22.JUL2016	GB
A6		ECR-24-225478	29OCT2024	EM

1 HOUSING WITH RETAINER

WATERPROOF / NOT WATERPROOF



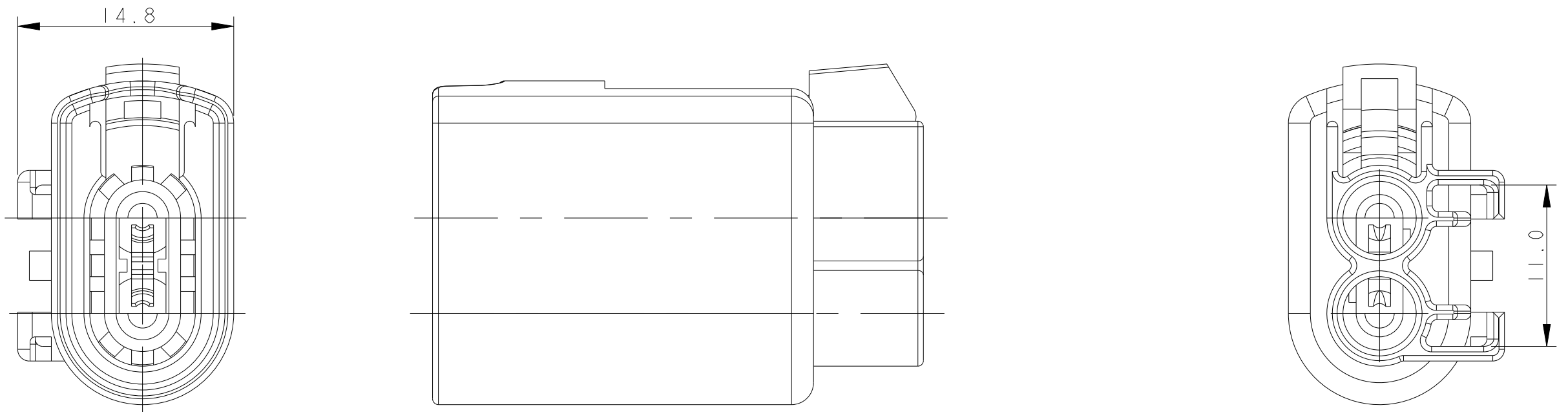


A4 HS MARKING - AT BLACK VERSION HOUSINGS WITH / WITHOUT RETAINER

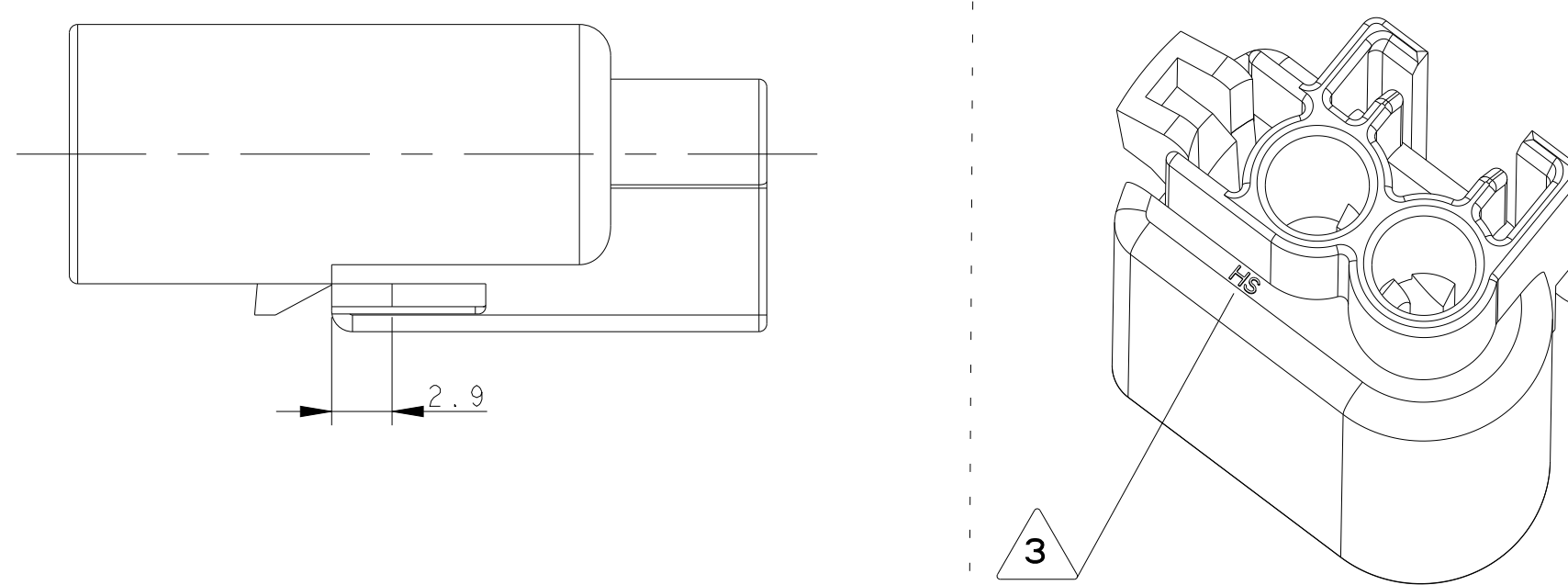


1 HOUSING WITHOUT RETAINER

WATERPROOF / NOT WATERPROOF

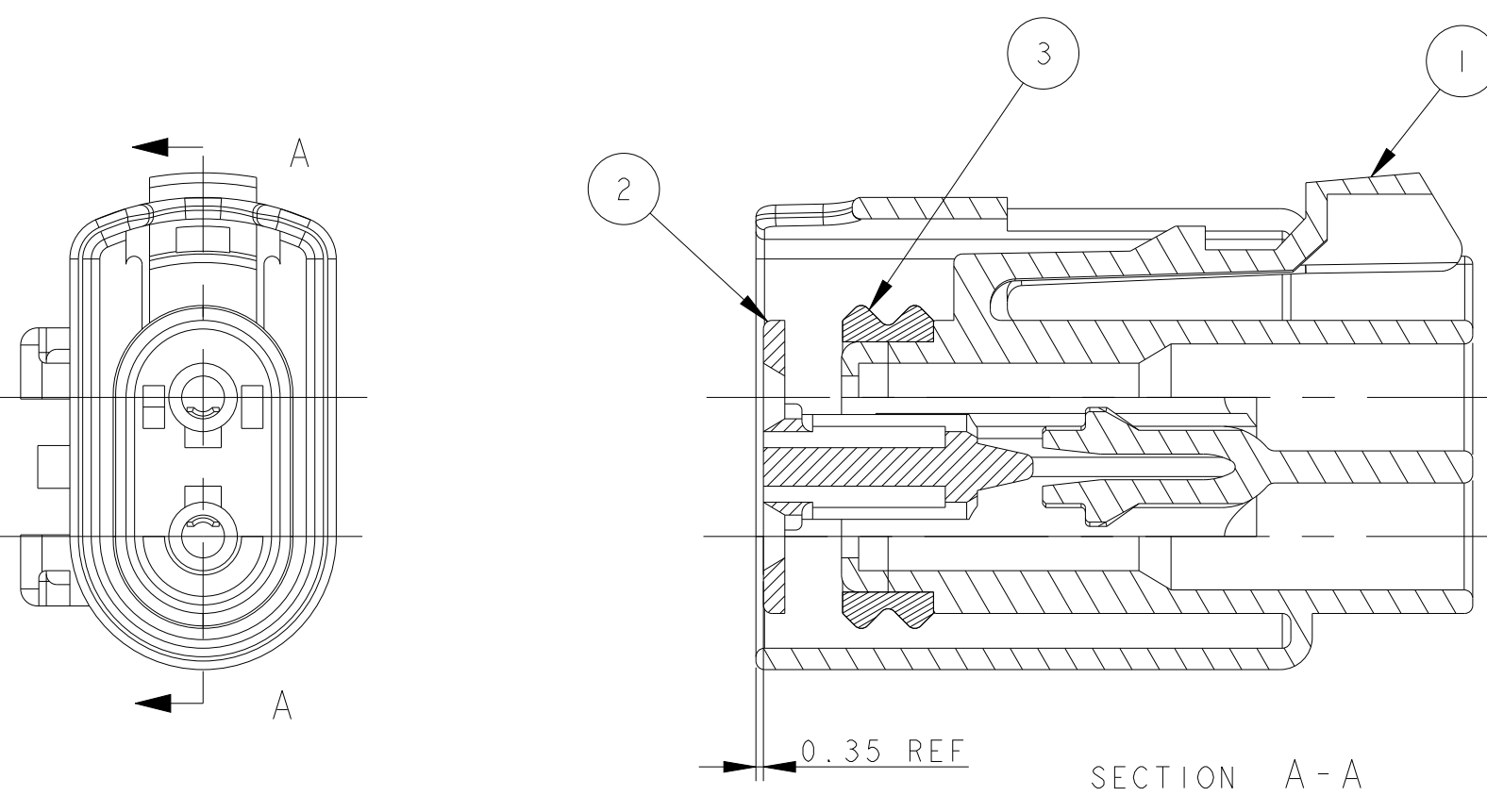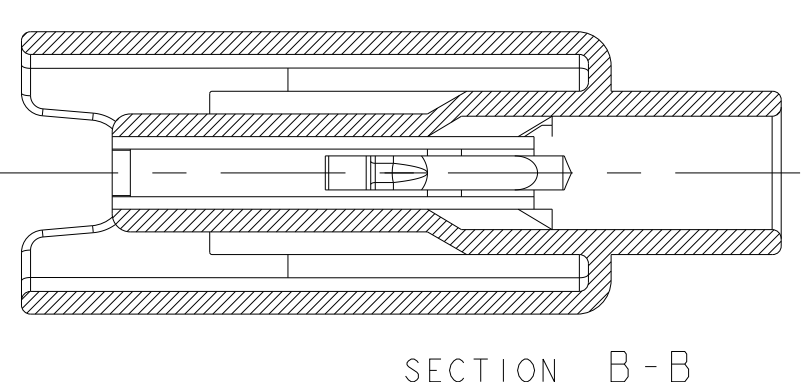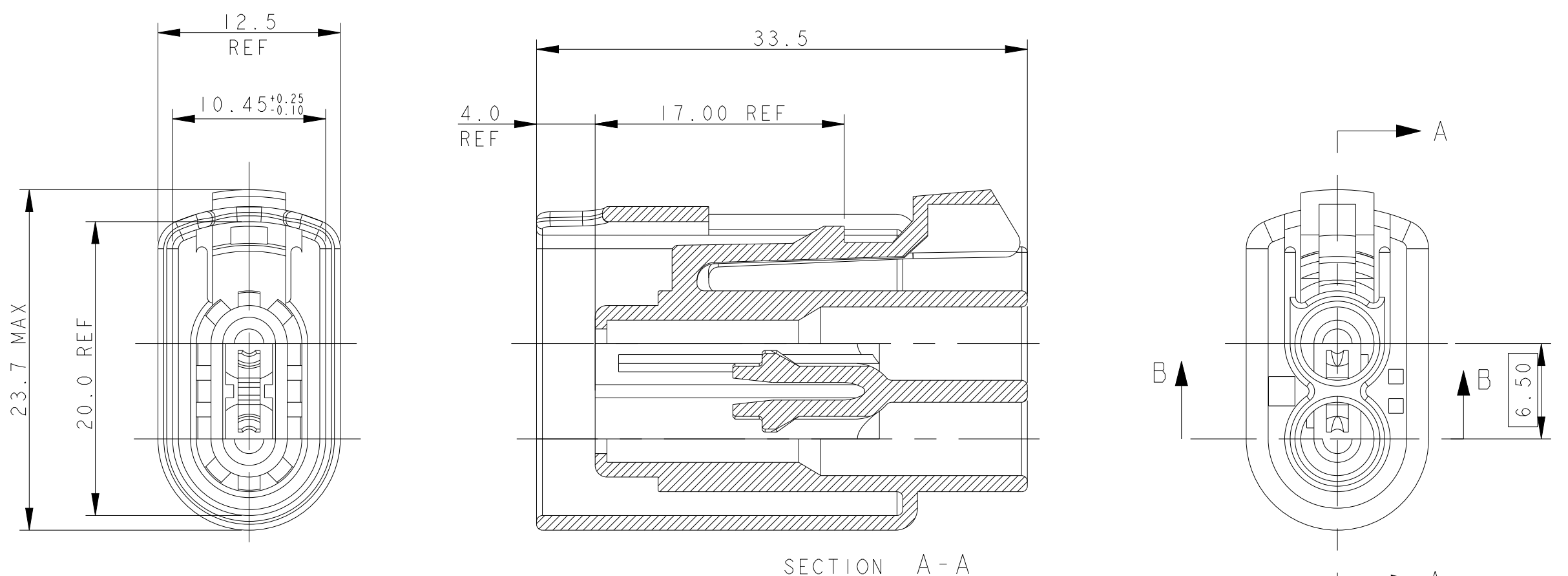

SCALE 4:1

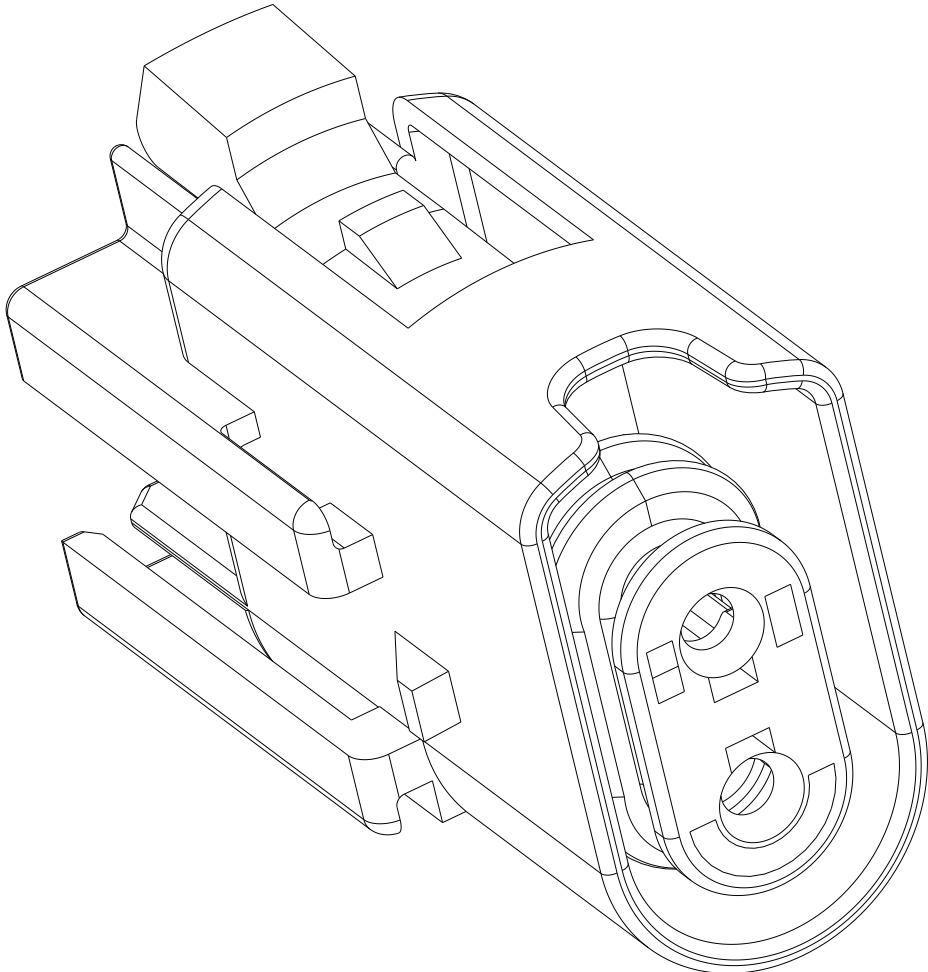

NOTES UNLESS OTHERWISE SPECIFIED:

- 1) SEE CHART FOR MATING PART NUMBERS.
- 2) THE CONNECTOR WITH AND WITHOUT RETAINER MOUNTING FEATURE IS DESIGNED TO PASS THROUGH A Ø 24.00mm MIN. HOLE

A4 3 HS MARKING - HIGH SPEED MATERIAL PBT GF 30 IN CASE BLACK HOUSING WITH / WITHOUT RETAINER VERSION ONLY

THIS DRAWING IS A CONTROLLED DOCUMENT.				REV D - 26MAY2008	CHG E - 26MAY2008	APPRO 26MAY2008	NAME 1.6mm SYSTEM 2 -WAYS CONNECTOR MALE	TE Connectivity	
DIMENSIONS:		TOLERANCES UNLESS OTHERWISE SPECIFIED:		PRODUCT SPEC		APPLICATION SPEC		SIZE CASE CODE DRAWING NO	
FORM		0 PLG ±0.3		2 PLG ±0.3		4 PLG ±0.3		WEIGHT	
MATERIAL		FINISH		Customer Drawing		RESTRICTED TO		SCALE 3:1	
SEE TABLES		-		-		A00779		SHEET 1 OF 2	

A4

2 WAY MALE, BLACK WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049
TE PART No.	1-1437710-8
T&B FORD PART No	NPITA-00R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	5-1437710-6

1 OBSOLETE, SUPERSEDED BY 5-1437710-6

2 WAY MALE, NATURAL WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049-N
TE PART No.	1-1437710-0
T&B FORD PART No	NPITA-N0R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	6-1437710-7

2 OBSOLETE, SUPERSEDED BY 6-1437710-7

2 WAY MALE, RED WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049-R
TE PART No.	1-1437710-1
T&B FORD PART No	NPITA-R0R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	7-1437710-0

3 OBSOLETE, SUPERSEDED BY 7-1437710-0

2 WAY MALE, GREY WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049-G
TE PART No.	6-1437710-4
T&B FORD PART No	NPITA-G0R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	6-1437710-4

2 WAY MALE, YELLOW WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049-Y
TE PART No.	7-1437710-3
T&B FORD PART No	NPITA-Y0R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	7-1437710-3

2 WAY MALE, BLUE WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106049-D
TE PART No.	0-1437710-9
T&B FORD PART No	NPITA-D0R2XX
FORD PART No	91AG-14A464-BBC
TE PART No.	6-1437710-0

4 OBSOLETE, SUPERSEDED BY 6-1437710-0

A4

2 WAY MALE, BLACK WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047
TE PART No.	5-1437710-5
T&B FORD PART No	NPITA-00Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	5-1437710-5

2 WAY MALE, NATURAL WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047-N
TE PART No.	6-1437710-6
T&B FORD PART No	NPITA-N0Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	6-1437710-6

2 WAY MALE, RED WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047-R
TE PART No.	-
T&B FORD PART No	NPITA-R0Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	-

2 WAY MALE, GREY WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047-G
TE PART No.	6-1437710-3
T&B FORD PART No	NPITA-G0Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	6-1437710-3

2 WAY MALE, YELLOW WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047-Y
TE PART No.	7-1437710-2
T&B FORD PART No	NPITA-Y0Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	7-1437710-2

2 WAY MALE, BLUE WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106047-D
TE PART No.	5-1437710-9
T&B FORD PART No	NPITA-D0Q2XX
FORD PART No	89FG-14A464-ABB
TE PART No.	5-1437710-9

A4

2 WAY MALE, BLACK NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050
TE PART No.	1-1437710-2
T&B FORD PART No	NPITA-00R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	5-1437710-8

5 OBSOLETE, SUPERSEDED BY 5-1437710-8

2 WAY MALE, NATURAL NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050-N
TE PART No.	6-1437710-9
T&B FORD PART No	NPITA-N0R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	6-1437710-9

2 WAY MALE, RED NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050-R
TE PART No.	7-1437710-1
T&B FORD PART No	NPITA-R0R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	7-1437710-1

2 WAY MALE, GREY NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050-G
TE PART No.	-
T&B FORD PART No	NPITA-G0R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	-

2 WAY MALE, YELLOW NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050-Y
TE PART No.	7-1437710-5
T&B FORD PART No	NPITA-Y0R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	7-1437710-5

2 WAY MALE, BLUE NON WATERPROOF VERSION WITH RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106050-D
TE PART No.	6-1437710-2
T&B FORD PART No	NPITA-D0R2XX
FORD PART No	91AG-14489-BBC
TE PART No.	6-1437710-2

A4

2 WAY MALE, BLACK NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048
TE PART No.	0-1437710-7
T&B FORD PART No	NPITA-0A02XX
FORD PART No	89FG-14489-ABB
TE PART No.	5-1437710-7

6 OBSOLETE, SUPERSEDED BY 5-1437710-7

2 WAY MALE, NATURAL NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048-N
TE PART No.	6-1437710-8
T&B FORD PART No	NPITA-NA02XX
FORD PART No	89FG-14489-ABB
TE PART No.	6-1437710-8

2 WAY MALE, RED NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048-R
TE PART No.	-
T&B FORD PART No	NPITA-RA02XX
FORD PART No	89FG-14489-ABB
TE PART No.	-




2 WAY MALE, GREY NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048-G
TE PART No.	6-1437710-5
T&B FORD PART No	NPITA-GA02XX
FORD PART No	89FG-14489-ABB
TE PART No.	6-1437710-5

2 WAY MALE, YELLOW NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048-Y
TE PART No.	7-1437710-4
T&B FORD PART No	NPITA-YA02XX
FORD PART No	89FG-14489-ABB
TE PART No.	7-1437710-4

2 WAY MALE, BLUE NON WATERPROOF VERSION WITHOUT RETAINER	
ASSEMBLY	
T&B UNIVERSAL PART No	106048-D
TE PART No.	6-1437710-1
T&B FORD PART No	NPITA-DA02XX
FORD PART No	89FG-14489-ABB
TE PART No.	6-1437710-1

2 WAY MALE, GREY WATERPROOF VERSION WITH EXTENDED SHROUD	
ASSEMBLY	
T&B PART No	2450159-001
FORD PART No	98AG-14A464-DBA
TE PART No.	0-1437710-1

7 IMPORTANT! ADD COLOUR AT ORDERS WITH FORD-PN's
E.G. 91AG-14A64-BBC RED

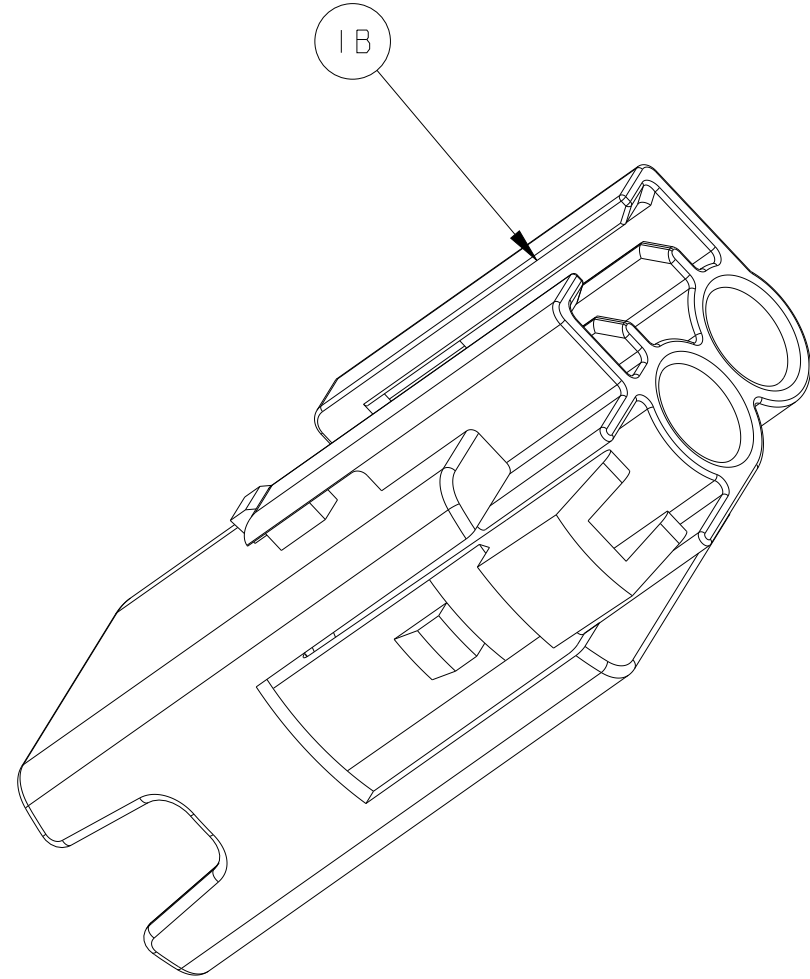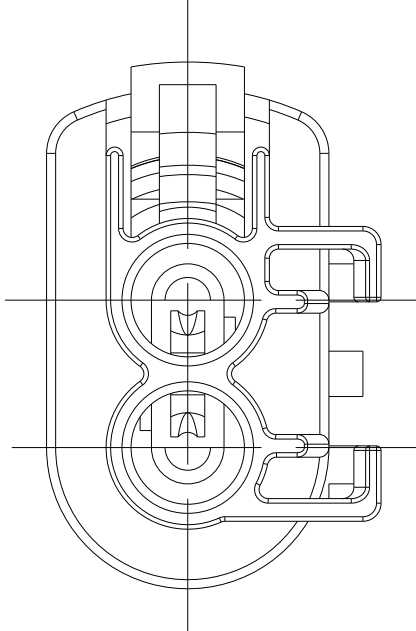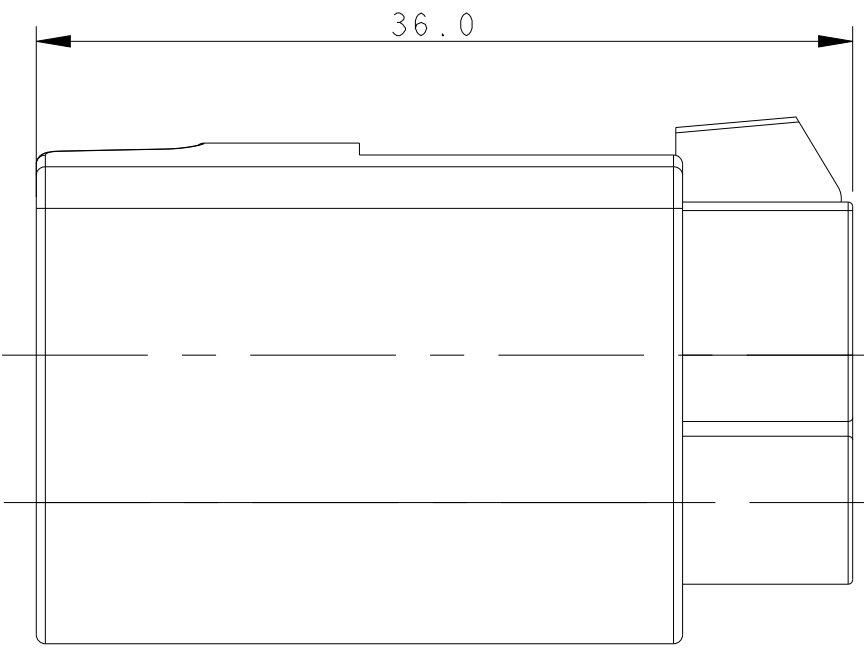

2 WAY MALE, GREY VERSION
P/N 0-1437710-1
WITH EXTENDED SHROUD

																				DESCRIPTION	ITEM
		I		I																HOUSING WITH RETAINER (BLACK)	I
		I		I																HOUSING WITHOUT RETAINER (BLACK)	I
					I		I													HOUSING WITH RETAINER (NATURAL)	I
					I		I													HOUSING WITHOUT RETAINER (NATURAL)	I
								I	I											HOUSING WITH RETAINER (RED)	I
																				HOUSING WITHOUT RETAINER (RED)	I
														I	I					HOUSING WITH RETAINER (YELLOW)	I
														I	I					HOUSING WITHOUT RETAINER (YELLOW)	I
															I					HOUSING WITH RETAINER (GRAY)	I
															I					HOUSING WITHOUT RETAINER (GRAY)	I
																I	I			HOUSING WITH RETAINER (BLUE)	I
																	I			HOUSING WITHOUT RETAINER (BLUE)	I
																		I		HOUSING WITH EXTENDED SHROUD WITH RETAINER (GRAY)	1B
				I	I												I	I		SPACER (RED)	2
		I	I			I	I							I	I					SPACER (LIGHT BLUE)	2
		I	I			I	I							I	I					SEAL (REDDISH BROWN)	3
5-1437710-5 REV/B																					
5-1437710-6 REV/B																					
5-1437710-7 REV/B																					
5-1437710-8 REV/B																					
6-1437710-6 REV/A																					
6-1437710-7 REV/A																					
6-1437710-8 REV/A																					
6-1437710-9 REV/A																					
7-1437710-0 REV/A																					
7-1437710-1 REV/A																					
6-1437710-3 REV/A																					
6-1437710-4 REV/A																					
6-1437710-5 REV/A																					
7-1437710-2 REV/A																					
7-1437710-3 REV/A																					
7-1437710-4 REV/A																					
7-1437710-5 REV/A																					
5-1437710-9 REV/A																					
6-1437710-0 REV/A																					
6-1437710-1 REV/A																					
6-1437710-2 REV/A																					
0-1437710-1 REV/A																					

A4

A4

PART AS SUPPLIED				COMPONENTS			COLOURS			MATERIALS		
TE PART No.	DESCRIPTION	WATERPROOF	WEIGHT	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL	1 HOUSING	2 SPACER	3 SEAL
-	2 WAY MALE CONNECTOR WITH EXTENDED SHROUD	YES	-	I	I	I	GRAY	LIGHT BLUE	REDDISH BROWN	PBTP 33% GF	PBTP 33% GF	SILICONE ELASTOMER
0-1437710-1	2 WAY MALE CONNECTOR WITH EXTENDED SHROUD WITH RETAINER		5.46 gr.	I	I	I						
-	2 WAY MALE CONNECTOR WITH EXTENDED SHROUD	NO	-	I	I		GRAY	RED		PBTP 33% GF	PBTP 33% GF	
-	2 WAY MALE CONNECTOR WITH EXTENDED SHROUD WITH RETAINER		-	I	I							

SUITABLE FOR		
TERMINAL FEMALE	WIRE SEAL	BLIND PLUG
0-1437709-9 (0.22-0.35mm ²) GOLD PLATED 1-1437709-0 (0.50-1.00mm ²) GOLD PLATED 1-1437709-7 (1.50mm ²) GOLD PLATED 1-1437709-4 (0.22-0.35mm ²) TIN PLATED 1-1437709-5 (0.50-1.00mm ²) TIN PLATED 1-1437709-6 (1.50mm ²) TIN PLATED	1-1437713-1 (0.22-0.35) BLACK 1-1437713-2 (0.50-1.00) RED 1-1437713-3 (1.50) BLUE	1-1437713-4
0-1437709-9 (0.22-0.35mm ²) GOLD PLATED 1-1437709-0 (0.50-1.00mm ²) GOLD PLATED 1-1437709-7 (1.50mm ²) GOLD PLATED 1-1437709-4 (0.22-0.35mm ²) TIN PLATED 1-1437709-5 (0.50-1.00mm ²) TIN PLATED 1-1437709-6 (1.50mm ²) TIN PLATED		

MATING PARTS	
TE PART No.	DESCRIPTION
-	2 WAY FEMALE CONNECTOR WATERPROOF
-	2 WAY FEMALE CONNECTOR NON WATERPROOF