




**Passive - 2 wire
16 Channel
Input
GE Fanuc**

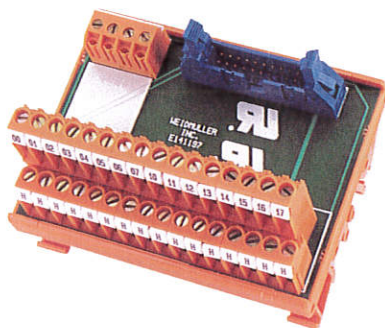




**Passive - 2 wire
16 Channel
Input w/LED
GE Fanuc**

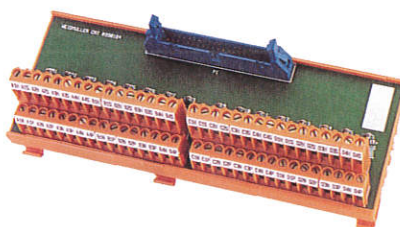

**Passive - 2 wire
16 Channel
Input
GE Fanuc**

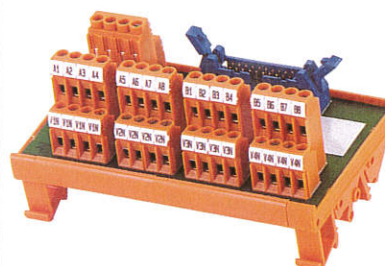

RS PLC 16PT DI +/- BUS			RS PLC IDI W/LED		RS PLC 16PT	
998041	24 VAC/DC	IC693MDL241	998184	IC697MDL240	998127	120 VAC IC697MDL251
	24 VDC	IC693MDL645, 646			998137	125 VDC IC697MDL640
998040	120 VAC	IC693MDL240				24 VDC IC697MDL671
See Above			120 VAC		See Above	
3.0 A per channel / 6.0 A per module / 3.0 A per common			2.5 A per channel / 12.0 A per module		3.0 A per channel / 3.0 A per group of 4 / 12.0 A per module	
(1) 1 x 20 pin IDC			(1) 1 x 40 pin IDC		(1) 1 x 20 pin IDC	
No			Yes		No	
0°C...+50°C			0°C...+50°C		0°C...+50°C	
-20°C...+60°C			-20°C...+60°C		-20°C...+60°C	
90 x 70 x 56			180 x 70 x 59		90 x 70 x 56	
#26...14 AWG			#26...14 AWG		#26...14 AWG	
Screw Clamp			Screw Clamp		Screw Clamp	

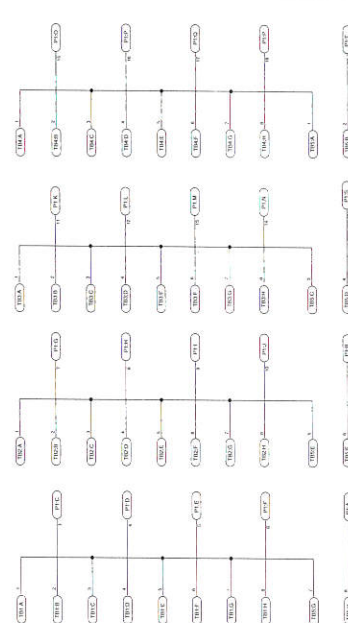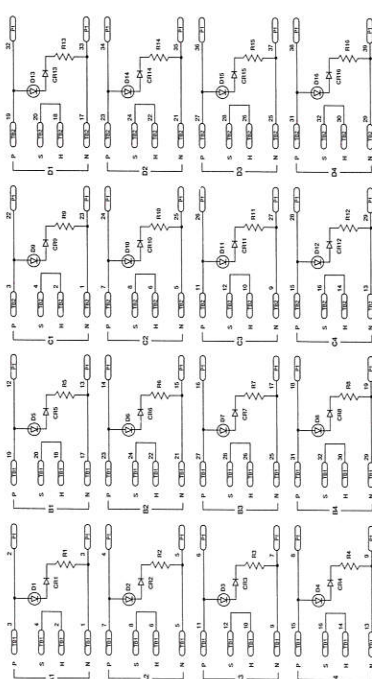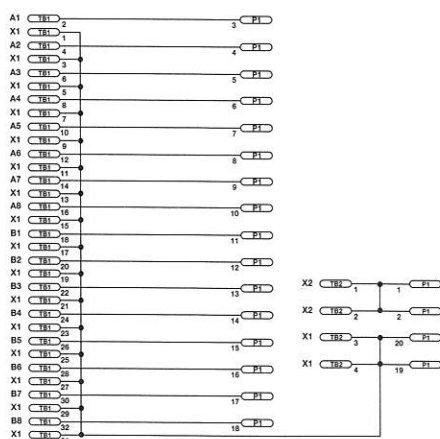

Note: Markings vary based on I/O used.

PART NUMBER SELECTION TABLES

Weidmüller