


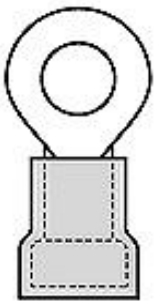

Part Number : [190570009](#)
Product Description : AviKrimp Ring Tongue
Terminal for 22-18 AWG Wire, Nylon, Stud Size 8,
26.08mm Length, Carton
Series Number : 19057
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : A-521-08



Documents & Resources

Drawings

[190570009 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19057
Description	AviKrimp Ring Tongue Terminal for 22-18 AWG Wire, Nylon, Stud Size 8, 26.08mm Length, Carton
Keyword	Ring Terminal, Ring Terminals
Product Name	Avikrimp
Style	Ring
Type	Ring Terminal, Metric Ring Terminal
UPC	800753057906

Agency

CSA	LR18689
UL	E32244

Electrical

Voltage - Maximum	600V
-------------------	------

Physical

Barrel Type	Closed
Color - Resin	Red
Flammability	94V-2

Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	0.998/g
Packaging Type	Carton
Stud Size	8 (M4)
Temperature Range - Operating	105°C
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	3.56mm max.
Wire Size (AWG)	18, 20, 22
Wire Size mm ²	0.25-1.50

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 22-10 AWG and 6.0-0.5mm ² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>640160036</u>