


Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- X-Lok >
- M Series >
- FLOS & FLOS+ >

- Accessory
- B Series A Size
- B Series B Size
- B Series C Size
- B Series D Size
- K Series B Size
- K Series C Size
- K Series D Size
- Y Series B Size

- Power >
- RBL >
- HS-Lok >
- NMEA 2000 >
- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

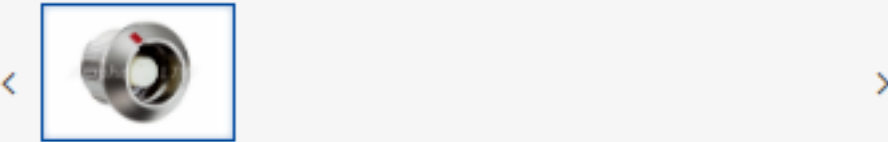

SLKC-S02EEFP-GCP-001

NEW

- Operating Temperature: -40°C ~ +125°C
- Transmission Speed: N/A
- Shielded: Metal, Shielded
- Jacket Material: N/A
- UL Certificate: N/A

You must login first for view the price

Quantity

-0+

Check Stock

Add to Cart

Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search

SPE, FLOS, Metal, 2A, 0...

SLKC-S02FMMM-GCP-...
-20°C ~ +80°C

-0+

SPE, FLOS, Metal, 2A, 0...

SLKC-S02FMMM-GCP-...
-20°C ~ +80°C

-0+

SPE, FLOS, Metal, 2A, 0...

SLKC-S02FMMM-GCP-...
-20°C ~ +80°C

-0+

SPE, FLOS, Metal, 2A, 0...

SLKC-S02FMMM-GCP-...
-20°C ~ +80°C

-0+

Add to Cart

Inquiry

Specifications	Download / CAD
Nominal Current 2A	Connector Type Receptacle
Shielded Metal, Shielded	No. of Contacts 02
Connector Gender Female	Backshell Circular
Mating Style Screw Thread	IP Rating IPX8
Assembly Style PCB 180°	
More Options	

People Also Bought

- SLKC-S02EEFP-...
- M12A-06BFFM-...
- BD-04BMMA-...
- UA-20AFMM-...
- M12A-12BFFM-...