


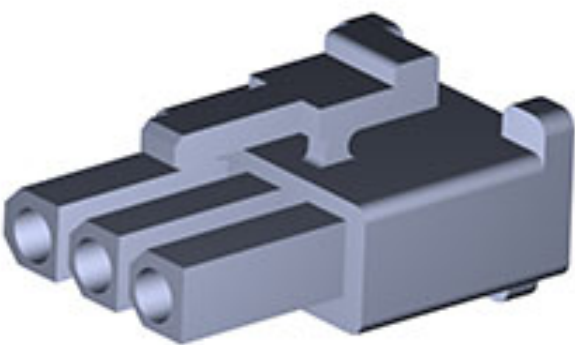

Part Number : [15311042](#)
Product Description : 4.80mm Pitch Wire-to-Wire Receptacle Housing, 4 Circuits
Series Number : 5025
Status : Active
Product Category : Connector Housings
Engineering Number : 5025-04R1



Documents & Resources

Drawings
[015311042_sd.pdf](#)
[SPK-5025-001-001.pdf](#)

Specifications
[PS-5025-001-001.pdf](#)
[PS-5025-002-001.pdf](#)
[PS-5025-003-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	5025
Description	4.80mm Pitch Wire-to-Wire Receptacle Housing, 4 Circuits
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	800753604575

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	4
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Net Weight	1824.500/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.80mm
Pitch - Termination Interface	4.80mm
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
4.80mm Pitch Wire-to-Wire Plug Housing, 4 Circuits	<u>15311041</u>
4.80mm Pitch Wire-to-Wire Plug Housing, 4 Circuits	<u>15311043</u>

Use with Part(s)

Description	Part Number
4.80mm Pitch Female Crimp Terminal	<u>5005</u>

This document was generated on Jan 31, 2025