



< List of part numbers with package codes >
ECASD90D567M4R5K00

Shape

L size	7.3 ±0.3mm
W size	4.3 ±0.3mm
T size	4.2 ±0.3mm
W1 size (max.)	2.4±0.2mm
S size	1.3±0.2mm
Size code in inch(mm)	2917(7343)

References

Packaging	Specifications	Minimum quantity
K	φ330mm Embossed taping	2000







Mass (typ.)	
1 piece	0.29g

Specifications

ESR (equivalent series resistance)	4.5mΩ
Capacitance	560μF ±20%
Rated voltage	2Vdc
Capacitance change rate	±20%
Operating temperature range	-40 to 105°C
Allowable Ripple Current	4.0Arms
Leakage Current	112.0μA

⚠ Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

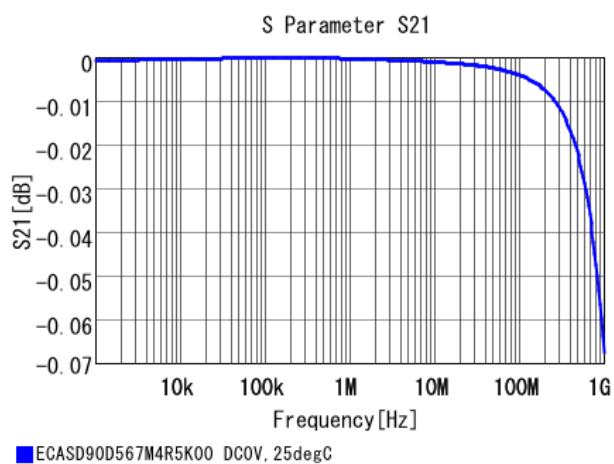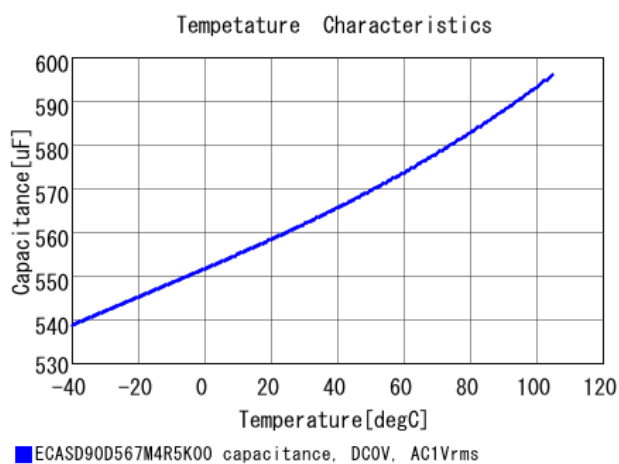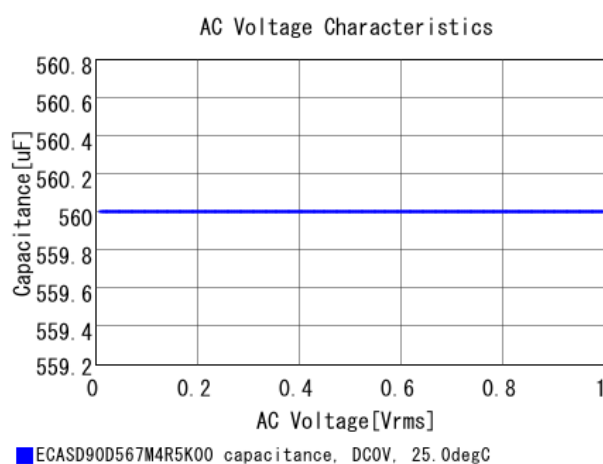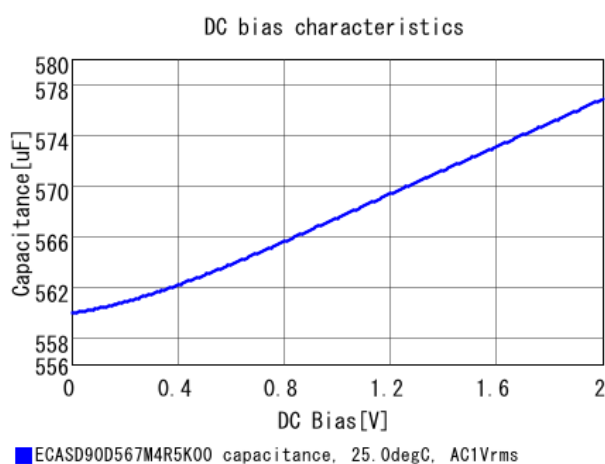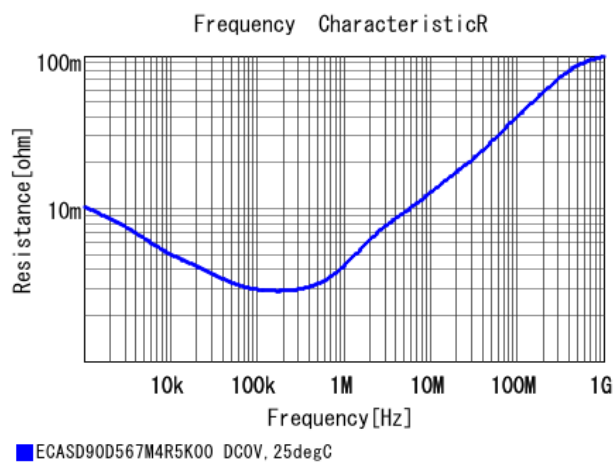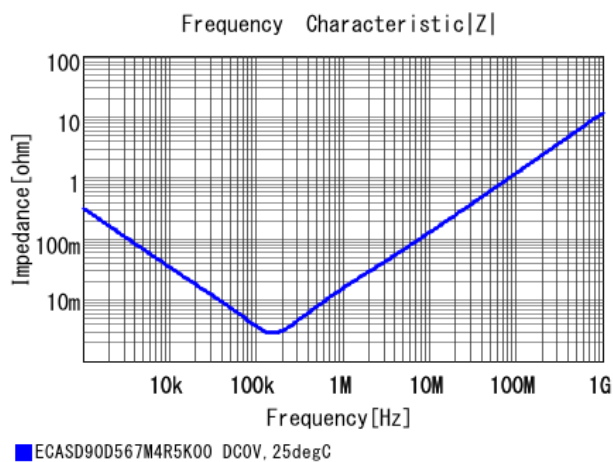

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.